

# Idler for plate chain



## DBL805

## For chain range 805


- For use with CAP805/SS plate chains

- Materials:

Low friction acetal

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

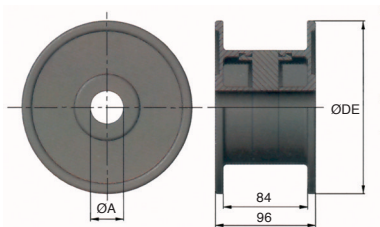

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

## Our other products



M0

Worm and wheel set,  
Hardened steel



PT881

Drive sprocket for slat  
top chain, Range 881



CHA\_GC\_9SS

Stainless steel garnet  
hinge, To be welded



BOX-TOR-ORFS

Box set of Nitrile O-  
rings NBR90Sh A, 7.65  
x 1.78mm to 37.82 x  
1.78




PRS100

Stainless steel  
articulated foot Ø100,  
Ø 100



CHINV

 Invisible hinge,  
Invisible - 90° opening



B

Steel bevel gear, 1:1



G3

Steel spur gear, Steel  
20NCD2



RCX-6

Spherical tilt washer -  
DIN6319, concave



HSE-HSB

Hexagonal spacer,  
Steel



SRG

Adjustable latch  
clamp with strike



BFM2

Flanged bronze nut,  
Bronze - 2 threads

## Complementary products



CAP805

Slat top chain  
stainless steel, Large  
range 805



PR821

Idler sprocket for slat  
top chain, Ranges 821  
and 805