

# Idler for plate chain



## DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal  
Stainless steel screws

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

### Advantage

- Two part design facilitates easy assembly

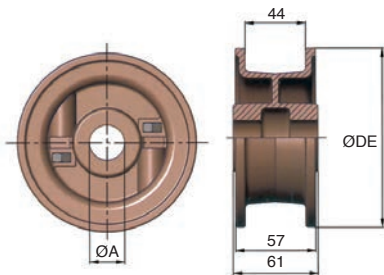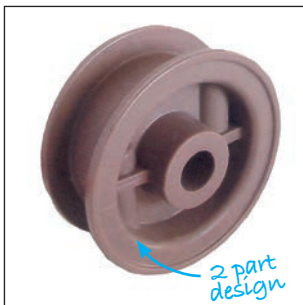

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request


Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	12,60 €
DBL820-21-30	129	30	0,3	12,60 €
DBL820-21-35	129	35	0,3	12,60 €
DBL820-21-40	129	40	0,3	12,60 €
DBL820-23-25	141	25	0,4	14,13 €
DBL820-23-30	141	30	0,4	14,13 €
DBL820-23-35	141	35	0,4	14,13 €
DBL820-23-40	141	40	0,4	14,55 €
DBL820-25-25	153	45	0,4	14,41 €
DBL820-25-30	153	30	0,4	14,41 €
DBL820-25-35	153	35	0,4	14,41 €
DBL820-25-40	153	40	0,4	14,41 €

Dimensions in mm

## Our other products



RDERSS  
Stainless steel manual rigging screw, Stainless steel - manual

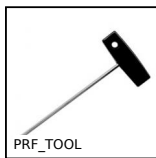

PRF\_TOOL  
Assembly key for aluminium profile, Assembly key



MDPOT  
Potentiometer,



PTRSS  
Idler chain sprocket, For hostile environments



Q1  
Self-aligning radial ball bearing, Steel



RDS  
Safety washer Hygienic Usit®, Stainless steel



PRF\_ECL  
Nut for aluminium profile, Stainless steel square nut with tab



AT5P\_AT10P  
Connecting plate for AT type timing belts, AT5



EFSM  
Igubal® flange bearing, Polymer



PRF4590  
Standard aluminium profile, 45 x 90 mm



VCMB  
Dual-thread screw wood/metal, Stainless steel



CLG3  
Moulded plastic spur gear, Moulded plastic (nylon)

## Complementary products



CAP820  
Slim slat top chain acetal, Narrow straight range 820



CAP815  
Slim slat top chain stainless steel, Narrow range 815



PT820  
Drive sprocket for slat top chain, Ranges 820 and 815



PR820  
Idler sprocket for slat top chain, Ranges 820 and 815