

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal
Stainless steel screws

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

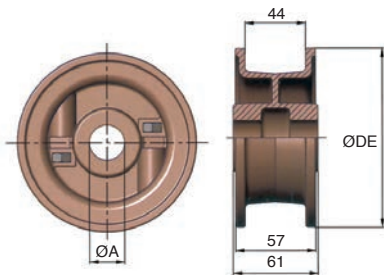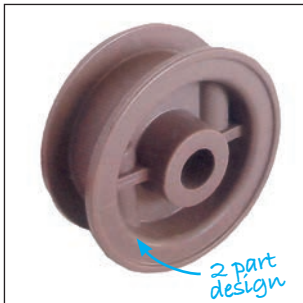

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	12,60 €
DBL820-21-30	129	30	0,3	12,60 €
DBL820-21-35	129	35	0,3	12,60 €
DBL820-21-40	129	40	0,3	12,60 €
DBL820-23-25	141	25	0,4	14,13 €
DBL820-23-30	141	30	0,4	14,13 €
DBL820-23-35	141	35	0,4	14,13 €
DBL820-23-40	141	40	0,4	14,55 €
DBL820-25-25	153	45	0,4	14,41 €
DBL820-25-30	153	30	0,4	14,41 €
DBL820-25-35	153	35	0,4	14,41 €
DBL820-25-40	153	40	0,4	14,41 €

Dimensions in mm

Our other products



 
METC

Flanged sintered bronze bush, Self-lubricating sintered bronze



BAN

Angular clamp, Standard



CXS

External circlip DIN471, external DIN 471



HW_HT

Half-rail guide, Wheel



CM

Tools Hygienic Usit® and Hygienic Design®, Combination spanner



LSAG

Precision linear rotary ball spline, Rail - from 514 N to 15386 N



GSI_A

Gas control screw for gas spring, Gas control screw



KH

Linear bearing, Light



TBD

Manual leadscrew table with opposing threads, 2kg



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



PRF_CLIP_22

Cable clip for aluminium profile, For electric and pneumatic cables



PRF_CH

Cable-carrier chain for aluminium profile, Supplied in metre lengths

Complementary products



CAP820

Slim slat top chain acetal, Narrow straight range 820



CAP815

Slim slat top chain stainless steel, Narrow range 815



PT820

Drive sprocket for slat top chain, Ranges 820 and 815



PR820

Idler sprocket for slat top chain, Ranges 820 and 815