

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal
Stainless steel screws

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

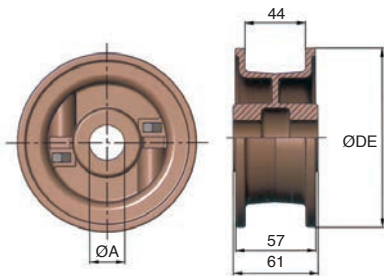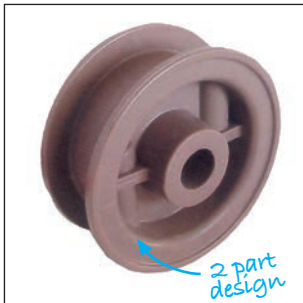

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	12,60 €
DBL820-21-30	129	30	0,3	12,60 €
DBL820-21-35	129	35	0,3	12,60 €
DBL820-21-40	129	40	0,3	12,60 €
DBL820-23-25	141	25	0,4	14,13 €
DBL820-23-30	141	30	0,4	14,13 €
DBL820-23-35	141	35	0,4	14,13 €
DBL820-23-40	141	40	0,4	14,55 €
DBL820-25-25	153	45	0,4	14,41 €
DBL820-25-30	153	30	0,4	14,41 €
DBL820-25-35	153	35	0,4	14,41 €
DBL820-25-40	153	40	0,4	14,41 €

 
Dimensions in mm

Our other products



PRF_SDD_1820

Support for Ø18 or Ø20mm Prox detector, Ø18 and Ø20



GPLso

Brush, silk



BLHB40

Right angled gearbox, bored shafts, up to 10.3 Nm



ERT

Sliding nut, For T slot



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



PTRSS

Idler chain sprocket, For hostile environments



S_2RS

Deep groove ball bearing, Stainless steel



SLBE

Indexing plunger - Spacer, Spacer for SLB and SLBS index bolts



R204

Die spring ISO10243, Average



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



EX

Optional shaft for E-type gear reducers, E Gearboxes double sided ou...

Complementary products



CAP820

Slim slat top chain acetal, Narrow straight range 820



CAP815

Slim slat top chain stainless steel, Narrow range 815



PT820

Drive sprocket for slat top chain, Ranges 820 and 815



PR820

Idler sprocket for slat top chain, Rangs 820 and 815