

# Idler for plate chain



## DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal  
Stainless steel screws

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

### Advantage

- Two part design facilitates easy assembly

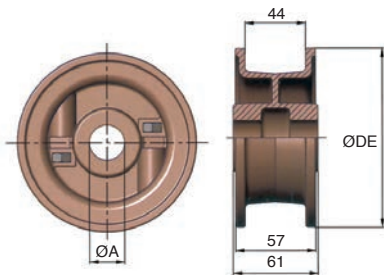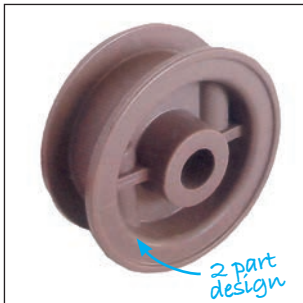

### DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	$\varnothing DE$	Bore $\varnothing A$	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	12,60 €
DBL820-21-30	129	30	0,3	12,60 €
DBL820-21-35	129	35	0,3	12,60 €
DBL820-21-40	129	40	0,3	12,60 €
DBL820-23-25	141	25	0,4	14,13 €
DBL820-23-30	141	30	0,4	14,13 €
DBL820-23-35	141	35	0,4	14,13 €
DBL820-23-40	141	40	0,4	14,55 €
DBL820-25-25	153	45	0,4	14,41 €
DBL820-25-30	153	30	0,4	14,41 €
DBL820-25-35	153	35	0,4	14,41 €
DBL820-25-40	153	40	0,4	14,41 €

Dimensions in mm

## Our other products



 
CFES  
Eccentric cam follower, Eccentric



RFVbr  
Stainless steel reaction arm, Reaction arm



QTR  
Tapered roller bearing, Steel



RPP  
Connecting plate for RPP type timing belts, RPP8



PCS\_PA6  
Plastic sprocket, 12.7mm (DIN 08B-1)



RJUM05  
Drylin R® linear bearing housing, Closed - Slim



GE\_C  
Spherical bushing, Hard chromium / PTFE



BLM  
Spring loaded plunger with ball tip, Stainless steel body



GGP  
Male wing knob, Technopolymer with stainless steel spindle



PR820  
Idle sprocket for slat top chain, Rangs 820 and 815



ACL-PR  
Joining plate for aluminium profile, Right angled



CHN\_CHNSS  
Straight long link chain, Galvanised steel

## Complementary products



CAP820  
Slim slat top chain acetal, Narrow straight range 820



CAP815  
Slim slat top chain stainless steel, Narrow range 815



PT820  
Drive sprocket for slat top chain, Ranges 820 and 815



PR820  
Idle sprocket for slat top chain, Rangs 820 and 815