

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Low friction acetal
Stainless steel screws



- Operating temp.: -40°C to +85°C

(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

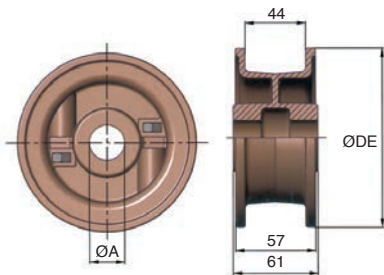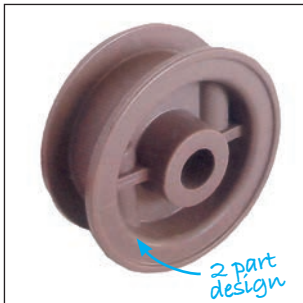

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	12,60 €
DBL820-21-30	129	30	0,3	12,60 €
DBL820-21-35	129	35	0,3	12,60 €
DBL820-21-40	129	40	0,3	12,60 €
DBL820-23-25	141	25	0,4	14,13 €
DBL820-23-30	141	30	0,4	14,13 €
DBL820-23-35	141	35	0,4	14,13 €
DBL820-23-40	141	40	0,4	14,55 €
DBL820-25-25	153	45	0,4	14,41 €
DBL820-25-30	153	30	0,4	14,41 €
DBL820-25-35	153	35	0,4	14,41 €
DBL820-25-40	153	40	0,4	14,41 €

Dimensions in mm

Our other products



MEB

Moulded plastic bevel gear (nylon), 1:1



LC

Friction clutch, 190 to 1800 Nm



RTT

Locking Assembly, Medium/high torque



PAT85

Pressed stainless steel articulating foot Ø85, Ø 85



SUPCC

Self-centering clamping hub steel, With lock nut



PRF_VTM

Hammerhead screw, Hammerhead screw



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



APBC

Circular rod, Round rod



BPPss

Pressed stainless steel pillow block, Stainless steel



VCMB

Dual-thread screw wood/metal, Stainless steel



CHM50

Worm and wheel gear reducer, up to 107 Nm

Complementary products



CAP820

Slim slat top chain acetal, Narrow straight range 820



CAP815

Slim slat top chain stainless steel, Narrow range 815



PT820

Drive sprocket for slat top chain, Ranges 820 and 815



PR820

Idler sprocket for slat top chain, Ranges 820 and 815