


- For use with CAP821 plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)
- For dimensions and bore tolerances, please refer to technical pages

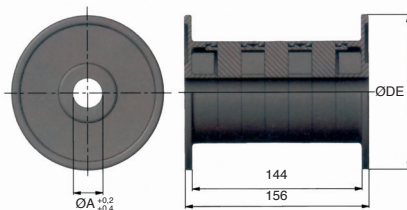

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL821-19-25	118,0	25	0,3	29,21 €
DBL821-19-30	118,0	30	0,3	29,21 €
DBL821-19-35	118,0	35	0,3	29,21 €
DBL821-19-40	118,0	40	0,3	29,21 €
DBL821-21-25	129,8	25	0,3	29,73 €
DBL821-21-30	129,8	30	0,3	29,73 €
DBL821-21-35	129,8	35	0,3	29,73 €
DBL821-21-40	129,8	40	0,3	29,73 €
DBL821-23-25	142,2	25	0,3	31,01 €
DBL821-23-30	142,2	30	0,3	31,01 €
DBL821-23-35	142,2	35	0,3	31,01 €
DBL821-23-40	142,2	40	0,3	31,01 €
DBL821-25-25	154,7	25	0,4	31,74 €
DBL821-25-30	154,7	30	0,4	31,74 €
DBL821-25-35	154,7	35	0,4	31,74 €
DBL821-25-40	154,7	40	0,4	31,74 €

Dimensions in mm

Our other products



PGT
Sliding profile, Sliding panel support



NSP
Right angled support clamp, Right angled support clamp



PT882
Drive sprocket for slat top chain, Range 882



 
CF
Cam follower, Standard - steel




JSM
Cylindrical polymer bush, Universal polymer



TCC_SS
Stainless steel rigging screw (hook/hook), Stainless steel



LAT4
4A motorised linear actuator, 4 amperes

 


TBL
Mini leadscrew table with metric thread, 1kg



RPCpl
Swivel castor with plate, Steel - Polyamide



 DIA
Ring operated locking bolt, with ring



LAT1
1A motorised linear actuator, 1 ampere



T10_21_AL_
T type timing pulley, Economy range - T10 aluminium

Complementary products



CAP821
Slat top chain acetal, Large range 821



PR821
Idler sprocket for slat top chain, Ranges 821 and 805