


- For use with CAP821 plate chains
- Materials:
  - Low friction acetal
- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)
- For dimensions and bore tolerances, please refer to technical pages

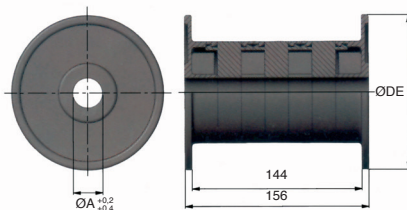

### DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL821-19-25	118,0	25	0,3	29,21 €
DBL821-19-30	118,0	30	0,3	29,21 €
DBL821-19-35	118,0	35	0,3	29,21 €
DBL821-19-40	118,0	40	0,3	29,21 €
DBL821-21-25	129,8	25	0,3	29,73 €
DBL821-21-30	129,8	30	0,3	29,73 €
DBL821-21-35	129,8	35	0,3	29,73 €
DBL821-21-40	129,8	40	0,3	29,73 €
DBL821-23-25	142,2	25	0,3	31,01 €
DBL821-23-30	142,2	30	0,3	31,01 €
DBL821-23-35	142,2	35	0,3	31,01 €
DBL821-23-40	142,2	40	0,3	31,01 €
DBL821-25-25	154,7	25	0,4	31,74 €
DBL821-25-30	154,7	30	0,4	31,74 €
DBL821-25-35	154,7	35	0,4	31,74 €
DBL821-25-40	154,7	40	0,4	31,74 €

Dimensions in mm

## Our other products



VELprf  
Clip-on base for hook-and-loop strip,  
Polyamide



H02  
Single needle roller  
universal joint, Heavy  
duty



BPPE  
Ball transfer unit push  
fit, Light




RBNpl  
Fixed castor with  
plate, Steel - rubber



CABtool  
Fitting cable tools,  
Cutting tools



 NDS20  
Double cross clamp,  
Crossed



BETA  
Hitch pin, Hitch



PRF\_PSA  
Shaft support for  
aluminium profile,  
Linear guide shaft



PDM\_PDV  
Detectable plastic  
palm grip, by metal



DOMI80  
Accessories, Clamping  
lever



PPG  
Indexing plunger with  
flange, With



PSP  
Support profile, Panel  
support

## Complementary products



CAP821  
Slat top chain acetal,  
Large range 821



PR821  
Idler sprocket for slat  
top chain, Ranges 821  
and 805