


- For use with CAP821 plate chains
- Materials:
  - Low friction acetal
- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)
- For dimensions and bore tolerances, please refer to technical pages

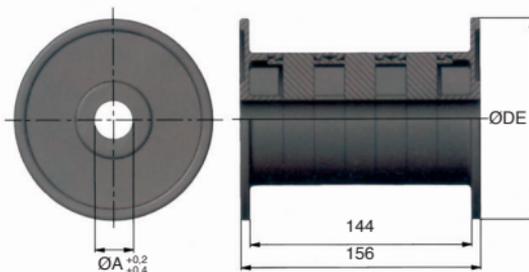

### DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL821-19-25	118,0	25	0,3	29,21 €
DBL821-19-30	118,0	30	0,3	29,21 €
DBL821-19-35	118,0	35	0,3	29,21 €
DBL821-19-40	118,0	40	0,3	29,21 €
DBL821-21-25	129,8	25	0,3	29,73 €
DBL821-21-30	129,8	30	0,3	29,73 €
DBL821-21-35	129,8	35	0,3	29,73 €
DBL821-21-40	129,8	40	0,3	29,73 €
DBL821-23-25	142,2	25	0,3	31,01 €
DBL821-23-30	142,2	30	0,3	31,01 €
DBL821-23-35	142,2	35	0,3	31,01 €
DBL821-23-40	142,2	40	0,3	31,01 €
DBL821-25-25	154,7	25	0,4	31,74 €
DBL821-25-30	154,7	30	0,4	31,74 €
DBL821-25-35	154,7	35	0,4	31,74 €
DBL821-25-40	154,7	40	0,4	31,74 €

Dimensions in mm

## Our other products



End cap for rectangular tube, Standard



Masterplate® gluable insert rectangular, rectangular with



Conical compression spring, Conical



Cylindrical threaded sleeve, Cylindrical - stainless steel



Male rod ends DIN ISO12240-4, Steel / bronze




Combined bearing with inner ring, Axial load in one direction



Steel splined shaft, Steel



Steel thread inserts, Steel

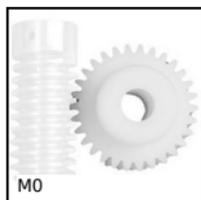

Worm and wheel set, Machined plastic



Miniature cam follower, Miniature



Flanged polymer nut, Polymer (Iglidur®) - 1



Storage bin, 8mm

## Complementary products



Slat top chain acetal, Large range 821



Idler sprocket for slat top chain, Ranges 821 and 805