


- For use with CAP821 plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)
- For dimensions and bore tolerances, please refer to technical pages

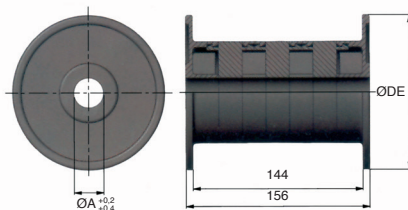

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL821-19-25	118,0	25	0,3	29,21 €
DBL821-19-30	118,0	30	0,3	29,21 €
DBL821-19-35	118,0	35	0,3	29,21 €
DBL821-19-40	118,0	40	0,3	29,21 €
DBL821-21-25	129,8	25	0,3	29,73 €
DBL821-21-30	129,8	30	0,3	29,73 €
DBL821-21-35	129,8	35	0,3	29,73 €
DBL821-21-40	129,8	40	0,3	29,73 €
DBL821-23-25	142,2	25	0,3	31,01 €
DBL821-23-30	142,2	30	0,3	31,01 €
DBL821-23-35	142,2	35	0,3	31,01 €
DBL821-23-40	142,2	40	0,3	31,01 €
DBL821-25-25	154,7	25	0,4	31,74 €
DBL821-25-30	154,7	30	0,4	31,74 €
DBL821-25-35	154,7	35	0,4	31,74 €
DBL821-25-40	154,7	40	0,4	31,74 €

Dimensions in mm

Our other products



SKM

Hexagonal steel nut,
Steel - 1 thread



RJUM05

Drylin R® linear
bearing housing,
Closed - Slim



PM2

Worm and wheel set,
Bronze



PSG255

Spur gear - precision
range, Stainless steel
316



BLHM30

Right angled gearbox,
double output shafts,
up to 4.4 Nm




SH4

Parallel axis helical
gear, Steel 20NCD2



TCXR

Automatic chain
tensioner, With
stainless steel
sprocket

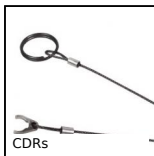

CDRs

Retaining cable for
ball pin, Retaining
cable



M0

Worm and wheel set,
Unhardened steel



H2

Crossed helical gear
crossed axis at 90°,



CMAss

Eye bolt stainless
steel, Stainless steel



DOMI50

Accessories, Clamping
lever

Complementary products



CAP821

Slat top chain acetal,
Large range 821



PR821

Idle sprocket for slat
top chain, Ranges 821
and 805