


- For use with CAP821 plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)
- For dimensions and bore tolerances, please refer to technical pages

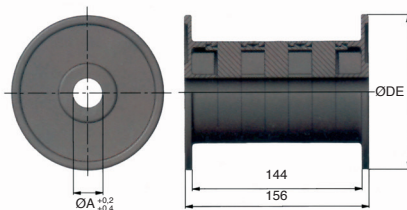

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL821-19-25	118,0	25	0,3	29,21 €
DBL821-19-30	118,0	30	0,3	29,21 €
DBL821-19-35	118,0	35	0,3	29,21 €
DBL821-19-40	118,0	40	0,3	29,21 €
DBL821-21-25	129,8	25	0,3	29,73 €
DBL821-21-30	129,8	30	0,3	29,73 €
DBL821-21-35	129,8	35	0,3	29,73 €
DBL821-21-40	129,8	40	0,3	29,73 €
DBL821-23-25	142,2	25	0,3	31,01 €
DBL821-23-30	142,2	30	0,3	31,01 €
DBL821-23-35	142,2	35	0,3	31,01 €
DBL821-23-40	142,2	40	0,3	31,01 €
DBL821-25-25	154,7	25	0,4	31,74 €
DBL821-25-30	154,7	30	0,4	31,74 €
DBL821-25-35	154,7	35	0,4	31,74 €
DBL821-25-40	154,7	40	0,4	31,74 €

Dimensions in mm

Our other products



BLM

Spring loaded plunger with ball tip, Plastic body



NTMbr

Set screw brass tip, Brass-point



HAS

Captive C washer, Slotted flat headed shoulder screw



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze



CHTRP

Single and dual output gearboxes, Up to 87,3 Nm



BOX-TOR-ORFS

Box set of Nitrile O-rings NBR90Sh A, 7.65 x 1.78mm to 37.82 x 1.78



712_001

Ball knob, spherical



DOMI80

Accessories, Clamping lever



ACL-FPA

Panel mounting block for aluminium structures, Angular



ZDB

Machined plastic bevel gear, 2:1



AT5M_AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



T5-16ECO

T type timing pulley, Economy range - T5 aluminium

Complementary products



CAP821

Slat top chain acetal, Large range 821



PR821

Idler sprocket for slat top chain, Ranges 821 and 805