




Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
 - Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

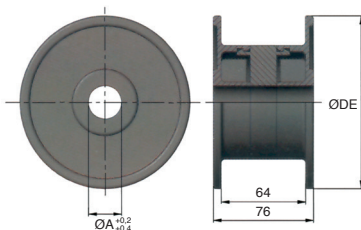


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

 Our other products



TBV
Manual lifting tables,
12kg



 
BPHT
Ball transfer unit bolt
fitting, Heavy



ACA
Steel splined shaft,
Steel



UGPC
Actuator guide kit,
Short bearing



CT
Telescopic universal
joint, Normal duty



SHWbr
Washer - DIN125,
Brass



GB-RA
Brass spur gear, Brass
CuZn39Pb3



SLB
Indexing plunger,
steel class 5.8




JCSs
Single stainless steel
universal joint, Low



PTA50
Articulated levelling
foot, pressed base



 ACLERP
Roller block for
aluminium profile,



PX_PO
Carrying handle, back-
plated

Complementary products



CAP880
Side flexing slim slat
top chain acetal,
Narrow range 880



PR880
Idler sprocket for slat
top chain, Range 880