




Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
 - Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

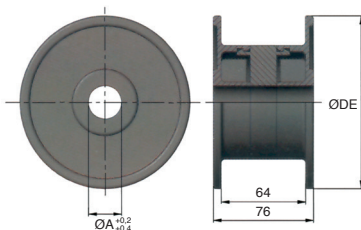

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

Our other products



CHC

Socket headed screw,
Steel class 12.19



MHXred

Reducing sleeve
male/female,
Hexagonal - steel



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...



MPS

Hexagonal spacer,
Stainless steel 303



NT122

Spur gear coaxial
gearbox, from 32 to
85 Nm - Inline



PR105

Articulated foot Ø103,
Ø 103



FBL6000_K1

Brush strip per meter
PA6 fibres Ø0.2 to
Ø0.3, Black polyamide
6 -...



CHTRB

Single and dual
output gearboxes, Up
to 53,1 Nm



SH2

Parallel axis helical
gear, Steel 20NCD2



ZBconique

Machined plastic
bevel gear, 1:1



TFR

Rigid manual
tensioner, Fixed



AT5-16ECO

AT type timing pulley,
Economy range - AT5
aluminium

Complementary products



CAP880

Side flexing slim slat
top chain acetal,
Narrow range 880



PR880

Idler sprocket for slat
top chain, Range 880