

Idler for slat top chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Self lubricating acetal

Stainless steel screws

- Operating temp.: -40°C to +85°C

(+70°C in humid environments)



- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

Accessory

- Plastic clamping ring BAP (tome 5 p.88-89)

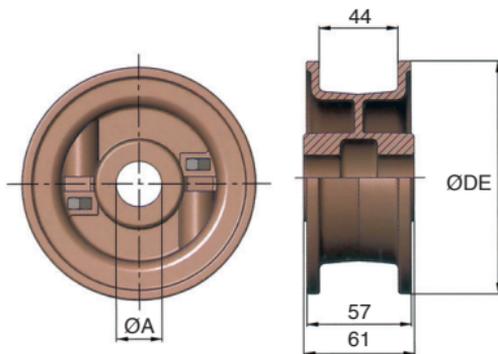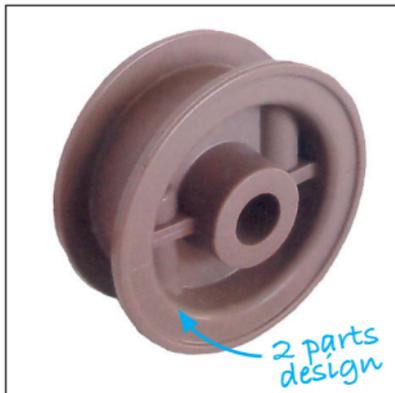

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request


Part number	$\varnothing DE$	Bore $\varnothing A$	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	16,84 €
DBL820-21-30	129	30	0,3	16,84 €
DBL820-21-35	129	35	0,3	16,84 €
DBL820-21-40	129	40	0,3	16,84 €
DBL820-23-25	141	25	0,4	18,91 €
DBL820-23-30	141	30	0,4	18,91 €
DBL820-23-35	141	35	0,4	18,91 €
DBL820-23-40	141	40	0,4	18,91 €
DBL820-25-25	153	45	0,4	18,46 €
DBL820-25-30	153	30	0,4	18,46 €
DBL820-25-35	153	35	0,4	18,46 €
DBL820-25-40	153	40	0,4	18,46 €

Dimensions in mm

- For use with CAP880T plate chains
- Materials:
Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.88-89)

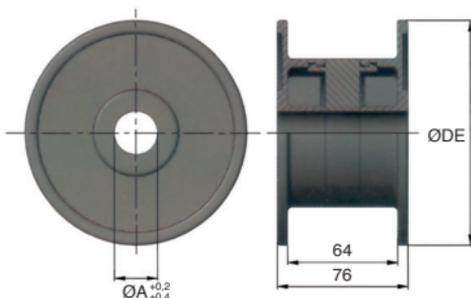

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	16,14 €
DBL880-19-30	117	30	0,3	16,14 €
DBL880-19-35	117	35	0,3	16,14 €
DBL880-19-40	117	40	0,3	16,14 €
DBL880-21-25	129	25	0,3	16,83 €
DBL880-21-30	129	30	0,3	16,83 €
DBL880-21-35	129	35	0,3	16,83 €
DBL880-21-40	129	40	0,3	16,83 €
DBL880-23-25	141	25	0,3	18,65 €
DBL880-23-30	141	30	0,3	18,65 €
DBL880-23-35	141	35	0,3	18,65 €
DBL880-23-40	141	40	0,3	18,66 €
DBL880-25-25	153	25	0,4	19,64 €
DBL880-25-30	153	30	0,4	19,64 €
DBL880-25-35	153	35	0,4	19,64 €
DBL880-25-40	153	40	0,4	19,64 €

Dimensions in mm