




Idler for slat top chain

For chain ranges 880 TAB and 881 TAB **DBL880**

- For use with CAP880T plate chains
- Materials:
 - Self lubricating acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

Accessory

- Plastic clamping ring BAP (tome 5 p.94-95)

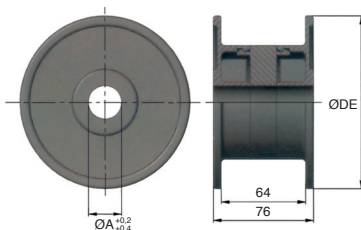

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	117	25	0,3	11,71 €
DBL880-19-30	117	30	0,3	11,71 €
DBL880-19-35	117	35	0,3	11,71 €
DBL880-19-40	117	40	0,3	11,71 €
DBL880-21-25	129	25	0,3	12,21 €
DBL880-21-30	129	30	0,3	12,21 €
DBL880-21-35	129	35	0,3	12,21 €
DBL880-21-40	129	40	0,3	12,21 €
DBL880-23-25	141	25	0,3	13,53 €
DBL880-23-30	141	30	0,3	13,53 €
DBL880-23-35	141	35	0,3	13,53 €
DBL880-23-40	141	40	0,3	13,43 €
DBL880-25-25	153	25	0,4	14,24 €
DBL880-25-30	153	30	0,4	14,24 €
DBL880-25-35	153	35	0,4	14,24 €
DBL880-25-40	153	40	0,4	14,24 €

Dimensions in mm

Our other products



Right angle helical reducers, from 0.60 to 3.84 Nm



HTD Heavy duty timing pulley, HTD5 Aluminium



Moulded plastic bevel gear (nylon), 1:1



Articulated foot whit sheet metal base Ø40, Ø 40



Mushroom headed button Hygienic Usit®, With male thread and high head



Stainless steel worm and wheel gearboxes, Mounting bracket



T type timing belt per metre, T10 Steel cored polyurethane



Ball pin socket, Mounting collar with a round flange



Moulded plastic bevel gear (nylon), 3:1



Indexing plunger, stainless steel



Nut for toggle clamp, Round ended nut for SLH/SLV clamp



Suction cup, 2.5 bellows, natural rubber

Complementary products



Side flexing slim slat top chain acetal, Narrow range 880



Idler sprocket for slat top chain, Range 880