



- Materials:
 - nitrile (NBR) : black color
 - silicone (SI) : translucent
 - natural rubber (NR) : grey color

Uses

- For moving parts with uneven surfaces

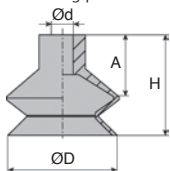


DCA05 to DCA16

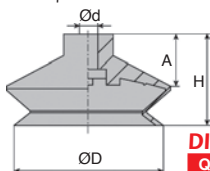

DCA20 to DCA43

Natural rubber

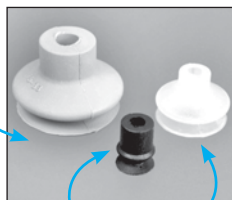

Nitrile

Silicone

DISCOUNTS

Qty	1+	50+	100+	150+	200+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	H	Ød	A	Corresponding thread insert	Stock*	Price each 1 to 49
Nitrile							
DCA05-NBR	5,5	11,1	4	8,0	TM5M5	✓	4,67 €
DCA11-NBR	11,0	16,0	4	10,5	CTM10M5	✓	4,04 €
DCA14-NBR	13,0	15,8	4	11,0		-	4,22 €
DCA16-NBR	16,0	19,0	4	10,5		✓	4,34 €
DCA20-NBR	19,0	15,8	4	10,5		✓	4,42 €
DCA22-NBR	22,0	19,5	4	11,0	-	4,61 €	
DCA25-NBR	24,0	23,0	4	16,5	-	4,81 €	
DCA33-NBR	33,0	28,0	8	16,5	SCR30M6	-	5,00 €
DCA43-NBR	43,0	28,0	8	15,5		✓	5,32 €
Silicone							
DCA05-SI	5,5	11,1	4	8,0	TM5M5	-	6,19 €
DCA11-SI	11,0	16,0	4	10,5	CTM10M5	✓	5,00 €
DCA14-SI	13,0	15,8	4	11,0		-	5,40 €
DCA16-SI	16,0	19,0	4	10,5		-	5,40 €
DCA20-SI	19,0	15,8	4	10,5		✓	5,40 €
DCA22-SI	22,0	19,5	4	11,0	✓	5,40 €	
DCA25-SI	24,0	23,0	4	16,5	✓	5,60 €	
DCA33-SI	33,0	28,0	8	16,5	SCR30M6	✓	6,19 €
DCA43-SI	43,0	28,0	8	15,5		✓	6,27 €
Natural rubber							
DCA05-NR	5,5	11,1	4	8,0	TM5M5	-	On request
DCA11-NR	11,0	16,0	4	10,5	CTM10M5	-	4,04 €
DCA14-NR	13,0	15,8	4	11,0		-	4,22 €
DCA16-NR	16,0	19,0	4	10,5		-	4,34 €
DCA20-NR	19,0	15,8	4	10,5		✓	4,42 €
DCA22-NR	22,0	19,5	4	11,0	-	8,41 €	
DCA25-NR	24,0	23,0	4	16,5	✓	4,61 €	
DCA33-NR	33,0	28,0	8	16,5	SCR30M6	-	5,00 €
DCA43-NR	43,0	28,0	8	15,5		✓	5,70 €

*Depending on availability - Dimensions in mm

Our other products




BAG-MI

Split shaft collar with clamp lever, Steel



PP35

 Worm and wheel gear reducer, from 2.20 to 4.10 Nm



TBV

Manual lifting tables, 3kg



PT882

Drive sprocket for slat top chain, Range 882



SSDB

Stainless steel bevel gear, 2:1



MFBS

Stainless steel flexible bellows coupling, Stainless steel - with se...



GSA_A

Adjustable gas spring, Steel



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2




MO

Worm and wheel set, Machined plastic (delrin)



CHAL3

 Piano hinge, Steel



SHNbr

Hexagonal nut DIN934, Brass



RAS

90° ball and socket joints DIN71802, Stainless steel

Complementary products



TM_CTM_CTF

Suction cup threaded insert, Insert for suction cup - Tread click-in



SCR

Suction cup threaded insert, Insert for suction cup - Socket screw