

Suction cup, 2.5 bellows



DCG For uneven and curved surfaces

- Suction cup to lift and move objects

- Materials:

nitrile (NBR) : black color, silicone (SI) : translucent,
natural rubber (NR) grey color

Natural rubber



Nitrile



Silicone

Uses

- For moving parts with irregular or curved surfaces
- These bellows allow for a more supple and faster grip, and also compensate for differences in height

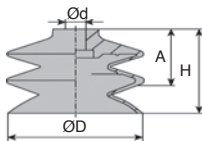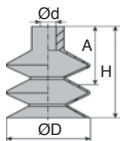

DCG07C to DCG25

DCG30 to DCG60

DISCOUNTS

Qty	1+	50+	100+	150+	200+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	H	Ød	A	Corresponding thread insert	Stock*	Price each 1 to 49
Nitrile							
DCG07C-NBR	7,0	14,2	4,0	10,0	CTM10M5	-	4,24 €
DCG10-NBR	9,0	15,0	5,0	12,0		✓	3,56 €
DCG15-NBR	15,2	22,0	5,0	12,0		✓	4,42 €
DCG18-NBR	17,5	23,0	5,0	13,0		-	4,61 €
DCG20-NBR	20,0	23,0	5,0	13,0		-	4,61 €
DCG25-NBR	25,0	33,0	4,5	19,34	-	4,61 €	
DCG30-NBR	32,0	37,5	8,0	23,0	-	5,00 €	
DCG40-NBR	42,0	46,0	8,0	24,0	SCR30M6	-	5,18 €
DCG60-NBR	62,0	55,0	8,0	28,0		-	7,91 €
Silicone							
DCG07C-SI	7,0	14,2	4,0	10,0	CTM10M5	-	5,40 €
DCG10-SI	9,0	15,0	5,0	12,0		✓	4,78 €
DCG15-SI	15,2	22,0	5,0	12,0		✓	5,40 €
DCG18-SI	17,5	23,0	5,0	12,0		✓	5,40 €
DCG20-SI	20,0	23,0	5,0	13,0		✓	5,60 €
DCG25-SI	25,0	33,0	4,5	19,34	✓	5,60 €	
DCG30-SI	32,0	37,5	8,0	23,0	✓	6,19 €	
DCG40-SI	42,0	46,0	8,0	24,0	SCR30M6	✓	6,19 €
DCG60-SI	62,0	55,0	8,0	28,0		-	9,43 €
Natural rubber							
DCG07C-NR	7,0	14,2	4,0	10,0	CTM10M5	-	3,56 €
DCG10-NR	9,0	15,0	5,0	12,0		-	3,56 €
DCG15-NR	15,2	22,0	5,0	12,0		-	4,42 €
DCG18-NR	17,5	23,0	5,0	12,0		-	4,61 €
DCG20-NR	20,0	23,0	5,0	13,0		-	4,61 €
DCG25-NR	25,0	33,0	4,5	19,34	-	4,61 €	
DCG30-NR	32,0	37,5	8,0	23,0	-	5,00 €	
DCG40-NR	42,0	46,0	8,0	24,0	SCR30M6	-	5,78 €
DCG60-NR	62,0	55,0	8,0	28,0		✓	8,49 €

*Depending on availability - Dimensions in mm

Our other products



MBEX
Hexagonal ended handle, Hexagonal ended handle




RPCtcss
Swivel castor with central hole, Stainless steel - Polyamide



AT10-50ECO
AT type timing pulley, Economy range - AT10 aluminium



 T5M T10M
T type timing belt per metre, T10 Steel cored polyurethane



PX_PO
Carrying handle, standard



RLR
Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting




UCP_PBT
Stainless/Polymer pillow block bearing, Polymer and stainless steel




BLHB20
Right angled gearbox, bored shafts, up to 1.77 Nm



 CLASS
Stainless steel indexing handle - female, Stainless steel



PRF45_GOU
Chute profile, Accessories

 

LAT4
4A motorised linear actuator, 4 amperes



RDERSS
Stainless steel manual rigging screw, Stainless steel - manual

Complementary products



TM_CTM_CTF
Suction cup threaded insert, Insert for suction cup - Tread click-in



SCR
Suction cup threaded insert, Insert for suction cup - Socket screw