



Socket with protective insert

Hygienic Design® and Usit®

DEP-HD

- Socket with protective plastic insert for mounting Hygienic Design® and Usit® products


- Materials:

Socket: tool steel

Insert: special PETP


Advantages

- 1/2" drive socket with a plastic insert to tighten and loosen screws and nuts in the Hygienic range. The plastic insert is made of special PETP and is FDA approved. The inserts are pressed into the socket by hand. Their special shape, combined with a clamping device, ensures optimal retention inside the socket.
- No special tools are required to replace worn plastic inserts.
- With a tightening torque (according to DIN standard for A4-70 screws and nuts, friction coefficient 0.12 μ) the inserts plastic have a life span of up to 1,000 cycles or more.

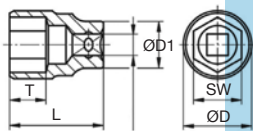

□12,5(1/2")

 DEP/HD socket



DEP/HD/INS insert

DISCOUNTS

Qty	1+	5+	10+
Disc	Net	-5%	On request

Part N°	ØD	ØD1	L	T	SW	SW1	Suitable for hexagonal screw	Price each
								1 to 4
Socket								
DEP-11/HD	16,6	22	37,3	10,1	11	-	-	25,65 €
DEP-13/HD	19,1	22	37,3	10,6	13	-	-	25,52 €
DEP-16/HD	22,9	23,6	37,1	11,3	16	-	-	26,87 €
DEP-19/HD	26,6	23	37,0	13,2	19	-	-	27,77 €
DEP-21/HD	29,0	25	36,8	12,9	21	-	-	43,21 €
DEP-27/HD	35,2	25	44,4	18,1	27	-	-	51,06 €
Protective insert								
DEP-8/HD/INS	-	-	18,0	6	11	8	M5	8,45 €
DEP-10/HD/INS	-	-	19,5	10	13	10	M6	8,52 €
DEP-13/HD/INS	-	-	21,5	11	16	13	M8	9,35 €
DEP-16/HD/INS	-	-	22,0	13,5	19	16	M10	9,82 €
DEP-18/HD/INS	-	-	21,5	12	21	18	M12	10,16 €
DEP-24/HD/INS	-	-	26,5	18	27	24	M16	14,51 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

61

Our other products



M1

Worm and wheel set,
Non hardened steel



RAS

90° ball and socket
joints DIN71802,
Stainless steel




SH2

Parallel axis helical
gear, Steel 20NCD2



PRF_P

Anchor foot for 45x45
profile, Anchor foot

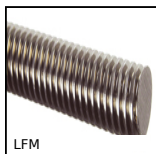

LFM

Steel leadscrew,
Medium carbon steel -
1 thread



BOX-TOR-MAX

Box set of Nitrile O-
rings in nitrile, 2.90 x
1.78mm to 82.14 x
3.53



TBL

Mini leadscrew table
with metric thread,
1kg



BVR

Adjustable screw stop,
Steel



CLG2

Moulded plastic spur
gear, Moulded plastic



 
SRP

Slotted spring pin
ISO8752, Split ISO



H1

Crossed helical gear
crossed axis at 90°



MR_MMR

Metric section rack,
Steel

Complementary products