

Extractable dowel pin **DIN 7979D** **Ste** **DIN** **Stock**


DHX

Hardened steel

- Easy extraction for holes where access is difficult or restricted
- External diameter tolerance: m6
- Material: hardened steel (DIN 7979D)
- Sold by the packet

Info.

- Ground flat along length allows air to escape during insertion/removal

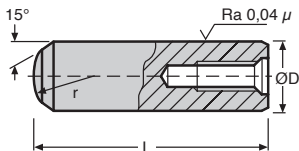

DISCOUNTS

| Qty | 1+ | 3+ | 5+ | 10+ |
|-------|------|------|------|------------|
| Disc. | List | -20% | -30% | On request |

| Part number | ØD m6 | Thread | Length L | Qty per packet | Price per packet |
|-------------|----------|--------|-------------|----------------------|------------------------|
| DHX4-10/B | 4 | M2 | 10 | 10 | ✓ 37,96 € |
| DHX4-12/B | 4 | M2 | 12 | 10 | ✓ 38,11 € |
| DHX4-14/B | 4 | M2 | 14 | 10 | ✓ 38,23 € |
| DHX4-16/B | 4 | M2 | 16 | 10 | ✓ 38,39 € |
| DHX4-20/B | 4 | M2 | 20 | 10 | ✓ 38,78 € |
| DHX5-10/B | 5 | M3 | 10 | 10 | ✓ 21,75 € |
| DHX5-12/B | 5 | M3 | 12 | 10 | ✓ 21,87 € |
| DHX5-16/B | 5 | M3 | 16 | 10 | ✓ 22,00 € |
| DHX5-20/B | 5 | M3 | 20 | 10 | ✓ 22,48 € |
| DHX5-24/B | 5 | M3 | 24 | 10 | ✓ 22,84 € |
| DHX5-30/B | 5 | M3 | 30 | 10 | ✓ 23,91 € |
| DHX6-12/B | 6 | M4 | 12 | 10 | ✓ 21,10 € |
| DHX6-16/B | 6 | M4 | 16 | 10 | ✓ 18,91 € |
| DHX6-20/B | 6 | M4 | 20 | 10 | ✓ 17,71 € |
| DHX6-24/B | 6 | M4 | 24 | 10 | ✓ 17,79 € |
| DHX6-30/B | 6 | M4 | 30 | 10 | ✓ 18,01 € |
| DHX6-40/B | 6 | M4 | 40 | 10 | ✓ 18,48 € |
| DHX6-60/B | 6 | M4 | 60 | 10 | ✓ 21,35 € |

| Part number | ØD m6 | Thread | Length L | Qty per packet | Price per packet |
|-------------|----------|--------|-------------|----------------------|------------------------|
| DHX8-16/B | 8 | M5 | 16 | 10 | ✓ 21,79 € |
| DHX8-20/B | 8 | M5 | 20 | 10 | ✓ 18,55 € |
| DHX8-24/B | 8 | M5 | 24 | 10 | ✓ 18,73 € |
| DHX8-28/B | 8 | M5 | 28 | 10 | ✓ 18,86 € |
| DHX8-30/B | 8 | M5 | 30 | 10 | ✓ 19,43 € |
| DHX8-40/B | 8 | M5 | 40 | 10 | ✓ 20,14 € |
| DHX8-50/B | 8 | M5 | 50 | 10 | ✓ 21,10 € |
| DHX10-20/B | 10 | M6 | 20 | 10 | ✓ 23,74 € |
| DHX10-24/B | 10 | M6 | 24 | 10 | ✓ 24,36 € |
| DHX10-30/B | 10 | M6 | 30 | 10 | ✓ 20,98 € |
| DHX10-40/B | 10 | M6 | 40 | 10 | ✓ 21,92 € |
| DHX10-45/B | 10 | M6 | 45 | 10 | - 22,52 € |
| DHX10-50/B | 10 | M6 | 50 | 10 | ✓ 23,17 € |
| DHX10-60/B | 10 | M6 | 60 | 10 | ✓ 24,36 € |
| DHX12-40/B | 12 | M6 | 40 | 10 | ✓ 25,00 € |
| DHX12-60/B | 12 | M6 | 60 | 10 | ✓ 29,11 € |
| DHX12-90/B | 12 | M6 | 90 | 10 | ✓ 46,13 € |
| DHX12-100/B | 12 | M6 | 100 | 10 | - 43,15 € |

*Depending on availability - Dimensions in mm

- For locking one part to another
- Relative positioning
- 15° chamfer
- Material: hardened steel 100 Cr6 rectified 58-60HRC
- Conforms to DIN 6325 (ISO 8734)
- For information on shear strength, please see technical information
- Sold by the packet




DISCOUNTS

| Qty | 1+ | 5+ | 10+ | 20+ |
|-------|------|------|------|------------|
| Disc. | List | -20% | -30% | On request |

| Part number | ØD m6 | Length L | Qty per packet | Stock* | Price each per packet |
|-------------|----------|-------------|-------------------|--------|--------------------------|
| DH1-5/B | 1,0 | 5 | 100 | ✓ | 6,41 € |
| DH1-6/B | 1,0 | 6 | 100 | ✓ | 6,41 € |
| DH1-5-5/B | 1,5 | 5 | 100 | ✓ | 4,72 € |
| DH1-5-6/B | 1,5 | 6 | 100 | ✓ | 6,41 € |
| DH1-5-8/B | 1,5 | 8 | 100 | ✓ | 5,34 € |
| DH1-5-10/B | 1,5 | 10 | 100 | ✓ | 5,58 € |
| DH2-6/B | 2,0 | 6 | 100 | ✓ | 5,34 € |
| DH2-8/B | 2,0 | 8 | 100 | ✓ | 5,66 € |
| DH2-10/B | 2,0 | 10 | 100 | ✓ | 5,89 € |
| DH2-12/B | 2,0 | 12 | 100 | ✓ | 6,23 € |
| DH2-14/B | 2,0 | 14 | 100 | ✓ | 6,65 € |
| DH2-16/B | 2,0 | 16 | 100 | ✓ | 7,01 € |
| DH2-30/B | 2,0 | 30 | 100 | ✓ | 18,48 € |
| DH2-5-10/B | 2,5 | 10 | 100 | ✓ | 6,25 € |
| DH2-5-12/B | 2,5 | 12 | 100 | ✓ | 6,41 € |
| DH3-6/B | 3,0 | 6 | 100 | ✓ | 5,58 € |
| DH3-8/B | 3,0 | 8 | 100 | ✓ | 5,37 € |
| DH3-10/B | 3,0 | 10 | 100 | ✓ | 5,66 € |
| DH3-12/B | 3,0 | 12 | 100 | ✓ | 5,98 € |
| DH3-16/B | 3,0 | 16 | 100 | ✓ | 6,77 € |
| DH3-18/B | 3,0 | 18 | 100 | ✓ | 7,18 € |
| DH3-20/B | 3,0 | 20 | 100 | ✓ | 7,46 € |
| DH3-24/B | 3,0 | 24 | 100 | ✓ | 8,16 € |
| DH3-30/B | 3,0 | 30 | 100 | ✓ | 9,32 € |
| DH3-32/B | 3,0 | 32 | 100 | ✓ | 9,66 € |
| DH3-40/B | 3,0 | 40 | 100 | ✓ | 14,52 € |
| DH4-6/B | 4,0 | 6 | 100 | ✓ | 6,80 € |
| DH4-8/B | 4,0 | 8 | 100 | ✓ | 6,74 € |

| Part number | ØD m6 | Length L | Qty per packet | Stock* | Price each per packet |
|-------------|----------|-------------|-------------------|--------|--------------------------|
| DH4-10/B | 4,0 | 10 | 100 | ✓ | 7,37 € |
| DH4-12/B | 4,0 | 12 | 100 | ✓ | 7,55 € |
| DH4-14/B | 4,0 | 14 | 100 | ✓ | 7,90 € |
| DH4-16/B | 4,0 | 16 | 100 | ✓ | 8,38 € |
| DH4-18/B | 4,0 | 18 | 100 | ✓ | 8,81 € |
| DH4-20/B | 4,0 | 20 | 100 | ✓ | 9,28 € |
| DH4-28/B | 4,0 | 28 | 100 | - | 11,04 € |
| DH4-30/B | 4,0 | 30 | 100 | ✓ | 11,45 € |
| DH4-32/B | 4,0 | 32 | 100 | - | 11,89 € |
| DH4-40/B | 4,0 | 40 | 100 | ✓ | 14,23 € |
| DH4-50/B | 4,0 | 50 | 100 | ✓ | 21,25 € |
| DH4-60/B | 4,0 | 60 | 100 | ✓ | 29,47 € |
| DH5-8/B | 5,0 | 8 | 25 | ✓ | 5,11 € |
| DH5-10/B | 5,0 | 10 | 25 | ✓ | 5,13 € |
| DH5-12/B | 5,0 | 12 | 25 | ✓ | 5,21 € |
| DH5-14/B | 5,0 | 14 | 25 | ✓ | 5,34 € |
| DH5-16/B | 5,0 | 16 | 25 | ✓ | 5,50 € |
| DH5-20/B | 5,0 | 20 | 25 | ✓ | 5,69 € |
| DH5-24/B | 5,0 | 24 | 25 | ✓ | 5,98 € |
| DH5-26/B | 5,0 | 26 | 25 | ✓ | 6,15 € |
| DH5-28/B | 5,0 | 28 | 25 | ✓ | 6,23 € |
| DH5-30/B | 5,0 | 30 | 25 | ✓ | 6,33 € |
| DH5-36/B | 5,0 | 36 | 25 | ✓ | 6,80 € |
| DH5-40/B | 5,0 | 40 | 25 | ✓ | 7,01 € |
| DH5-50/B | 5,0 | 50 | 25 | ✓ | 7,90 € |
| DH6-10/B | 6,0 | 10 | 25 | ✓ | 5,58 € |
| DH6-12/B | 6,0 | 12 | 25 | ✓ | 5,61 € |
| DH6-14/B | 6,0 | 14 | 25 | ✓ | 5,78 € |

 *Depending on availability - Dimensions in mm



DISCOUNTS

| Qty | 1+ | 5+ | 10+ | 20+ |
|-------|------|------|------|------------|
| Disc. | List | -20% | -30% | On request |

| Part number | ØD m6 | Length L | Qty per packet | Stock* | Price each per packet |
|-------------|----------|-------------|-------------------|--------|--------------------------|
| DH6-16/B | 6,0 | 16 | 25 | ✓ | 5,78 € |
| DH6-18/B | 6,0 | 18 | 25 | ✓ | 5,93 € |
| DH6-20/B | 6,0 | 20 | 25 | ✓ | 6,15 € |
| DH6-24/B | 6,0 | 24 | 25 | ✓ | 6,33 € |
| DH6-26/B | 6,0 | 26 | 25 | ✓ | 6,61 € |
| DH6-28/B | 6,0 | 28 | 25 | ✓ | 6,74 € |
| DH6-30/B | 6,0 | 30 | 25 | ✓ | 6,90 € |
| DH6-36/B | 6,0 | 36 | 25 | ✓ | 7,35 € |
| DH6-40/B | 6,0 | 40 | 25 | ✓ | 7,68 € |
| DH6-50/B | 6,0 | 50 | 25 | ✓ | 8,81 € |
| DH6-60/B | 6,0 | 60 | 25 | ✓ | 10,11 € |
| DH8-16/B | 8,0 | 16 | 25 | ✓ | 8,18 € |
| DH8-18/B | 8,0 | 18 | 25 | ✓ | 8,23 € |
| DH8-20/B | 8,0 | 20 | 25 | ✓ | 8,28 € |
| DH8-24/B | 8,0 | 24 | 25 | ✓ | 8,76 € |
| DH8-30/B | 8,0 | 30 | 25 | ✓ | 9,52 € |

| Part number | ØD m6 | Length L | Qty per packet | Stock* | Price each per packet |
|-------------|----------|-------------|-------------------|--------|--------------------------|
| DH8-40/B | 8,0 | 40 | 25 | ✓ | 10,71 € |
| DH8-50/B | 8,0 | 50 | 25 | ✓ | 12,19 € |
| DH8-80/B | 8,0 | 80 | 25 | ✓ | 20,51 € |
| DH10-20/B | 10,0 | 20 | 25 | ✓ | 9,66 € |
| DH10-26/B | 10,0 | 26 | 25 | ✓ | 11,01 € |
| DH10-30/B | 10,0 | 30 | 25 | ✓ | 11,82 € |
| DH10-36/B | 10,0 | 36 | 25 | ✓ | 13,14 € |
| DH10-40/B | 10,0 | 40 | 25 | - | 13,93 € |
| DH10-45/B | 10,0 | 45 | 25 | ✓ | 14,79 € |
| DH10-50/B | 10,0 | 50 | 25 | ✓ | 15,79 € |
| DH10-60/B | 10,0 | 60 | 25 | ✓ | 17,92 € |
| DH10-80/B | 10,0 | 80 | 25 | - | 24,81 € |
| DH12-20/B | 12,0 | 20 | 25 | - | 14,69 € |
| DH12-30/B | 12,0 | 30 | 25 | ✓ | 16,87 € |
| DH12-40/B | 12,0 | 40 | 25 | ✓ | 19,50 € |

*Depending on availability - Dimensions in mm

Our other products



KKP-AR

Linear bearing with inclined ball tracks, Heavy loads / -20° +200°



VTLF

3 lobed handle, Polyamide - Brass



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



ZAmM

Shaft for linear guides, Hardened ground steel



CHTRP

Single and dual output gearboxes, Up to 87,3Nm



PSG08

Spur gear - precision range, Pre-hardened Steel 35NCD6



RTE

Rotex®, jaw coupling, steel



RFV40

Stainless steel worm and wheel gearbox, up to 47 Nm



HCSS

Set screw with hexagonal socket, Cup point



EHD04

Internal epicyclic servo reducers, from 3.4 to 7 Nm



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



GAL48_OMNI

Omni-directional roller, Omni-directional

Complementary products



DP

Dowel pin, Solid ISO 2338



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



DH

Dowel pin, Solid DIN 6325