

# Extractable dowel pin **DIN 7979D** **Ste** **DIN** **Stock**


## DHX

## Hardened steel

- Easy extraction for holes where access is difficult or restricted
- External diameter tolerance: m6
- Material: hardened steel (DIN 7979D)
- Sold by the packet

### Info.

- Ground flat along length allows air to escape during insertion/removal

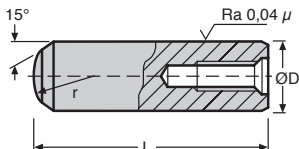

### DISCOUNTS

Qty	1+	3+	5+	10+
Disc.	List	-20%	-30%	On request

Part number	ØD	Thread	Length	Qty per packet	Price per packet
	m6		L	Stock*	
DHX4-10/B	4	M2,5	10	10	✓ 37,62 €
DHX4-12/B	4	M2,5	12	10	✓ 37,77 €
DHX4-14/B	4	M2,5	14	10	✓ 37,89 €
DHX4-16/B	4	M2,5	16	10	✓ 38,05 €
DHX4-20/B	4	M2,5	20	10	✓ 38,43 €
DHX4-24/B	4	M2,5	24	10	✓ 38,56 €
DHX4-30/B	4	M2,5	30	10	✓ 39,96 €
DHX4-40/B	4	M2,5	40	10	✓ 41,80 €
DHX5-10/B	5	M3	10	10	✓ 21,56 €
DHX5-12/B	5	M3	12	10	✓ 21,67 €
DHX5-16/B	5	M3	16	10	✓ 21,80 €
DHX5-18/B	5	M3	18	10	✓ 21,93 €
DHX5-20/B	5	M3	20	10	✓ 22,28 €
DHX5-24/B	5	M3	24	10	✓ 22,64 €
DHX5-30/B	5	M3	30	10	✓ 23,70 €
DHX5-36/B	5	M3	36	10	- 24,54 €
DHX5-40/B	5	M3	40	10	✓ 25,10 €
DHX5-50/B	5	M3	50	10	✓ 29,39 €
DHX6-12/B	6	M4	12	10	✓ 20,91 €
DHX6-14/B	6	M4	14	10	✓ 20,91 €
DHX6-16/B	6	M4	16	10	✓ 18,74 €
DHX6-18/B	6	M4	18	10	✓ 18,80 €
DHX6-20/B	6	M4	20	10	✓ 17,55 €
DHX6-24/B	6	M4	24	10	✓ 17,63 €

Part number	ØD	Thread	Length	Qty per packet	Price per packet
	m6		L	Stock*	
DHX6-28/B	6	M4	28	10	✓ 17,75 €
DHX6-30/B	6	M4	30	10	✓ 17,85 €
DHX6-40/B	6	M4	40	10	✓ 18,32 €
DHX6-60/B	6	M4	60	10	✓ 21,16 €
DHX8-16/B	8	M5	16	10	✓ 21,60 €
DHX8-20/B	8	M5	20	10	✓ 18,38 €
DHX8-24/B	8	M5	24	10	✓ 18,56 €
DHX8-28/B	8	M5	28	10	✓ 18,69 €
DHX8-30/B	8	M5	30	10	✓ 19,26 €
DHX8-40/B	8	M5	40	10	✓ 19,96 €
DHX8-50/B	8	M5	50	10	✓ 20,91 €
DHX10-16/B	10	M6	16	10	✓ 27,38 €
DHX10-20/B	10	M6	20	10	✓ 23,53 €
DHX10-24/B	10	M6	24	10	✓ 24,14 €
DHX10-30/B	10	M6	30	10	✓ 20,79 €
DHX10-40/B	10	M6	40	10	✓ 21,72 €
DHX10-45/B	10	M6	45	10	- 22,32 €
DHX10-50/B	10	M6	50	10	✓ 22,96 €
DHX10-60/B	10	M6	60	10	✓ 24,14 €
DHX12-40/B	12	M6	40	10	✓ 24,78 €
DHX12-60/B	12	M6	60	10	✓ 28,85 €
DHX12-90/B	12	M6	90	10	✓ 45,72 €
DHX12-100/B	12	M6	100	10	- 42,77 €

\*Depending on availability - Dimensions in mm

## Our other products



KB\_UU  
Closed linear  
precision bearing,  
Precision - steel



BEK  
Bearing housing for  
miniature ballscrew,  
Bearing housing



GA\_A  
Adjustable gas spring,  
Steel



BCA  
Steel splined collar,  
Steel




MET  
Cylindrical sintered  
bronze bush, Self-  
lubricating sintered  
bronze



VQT  
Quarter-turn clamp  
key, Plastic or  
stainless steel button



 DOMI120  
Accessories, Turntable




RPP14  
RPP heavy duty  
timing belt, RPP14



BPM\_LOK  
Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -



 KK  
Rounded end feather  
key, Steel



RPP  
Connecting plate for  
RPP type timing belts,  
RPP14



PNA\_R  
PERIFLEX elastic  
coupling,  
Replacement tyre

## Complementary products



DP  
Dowel pin, Solid ISO  
2338



BOXdhx  
Boxed set of threaded  
dowel pins DIN7979D,  
Boxed set -  
extractable D...



DH  
Dowel pin, Solid DIN  
6325