

Lever operated indexing plunger



DIL

Threaded body M6-M16

- Locking indexing plunger





- Material: steel (class 5.8)
- Finish: blue zinc plated

Info.

- Indexing plunger can be used where lateral movement needs to be restricted
- Raising the lever unlocks the bolt



Pull the lever to unlock

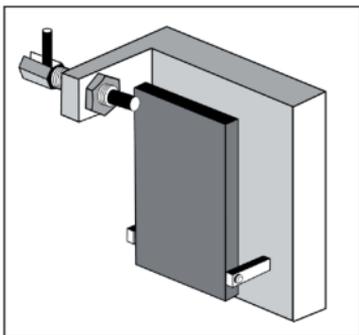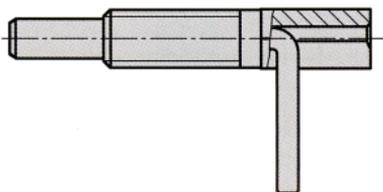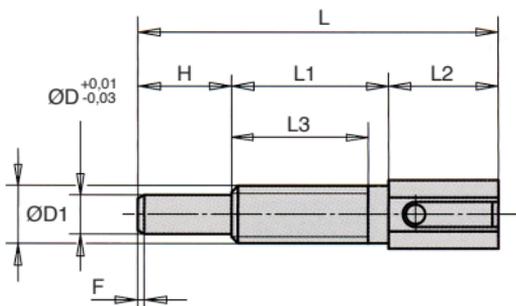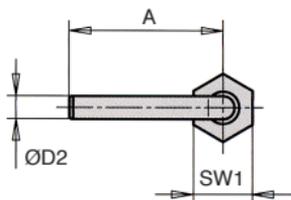

Typical application: locking

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	H	A	SW1	F	F _{x30°}	Spring strength			Stock*	Price each 1 to 5
													Initial F1 (N)	final F2 (N)	Tightening Force max (Nm)		
DIL6	4	M6	2,3	41,5	20,0	12,0	17,0	9,5	15,5	6	0,7	3	10	1,6	✓	7,68 €	
DIL10	6	M10	3,5	65,0	33,5	17,5	30,0	14,0	22,9	10	1,1	4	16	10,0	✓	8,73 €	
DIL12	8	M12	4,7	73,0	31,8	22,2	28,0	19,0	31,2	12	1,3	4	22	13,0	✓	10,02 €	
DIL16	10	M16	4,7	102,5	50,5	27,0	44,5	25,0	32,7	16	1,6	4	23	42,0	✓	13,89 €	

*Depending on availability - Dimensions in mm