

Lever operated locking bolt





DIL

Lift the lever to unlock


- Locking bolt
- Material: steel (class 5.8)
- Finish: blue zinc plated

Info.

- Locking bolts can be used where lateral movement needs to be restricted
- Raising the lever unlocks the bolt

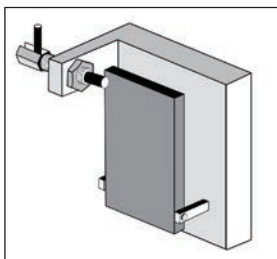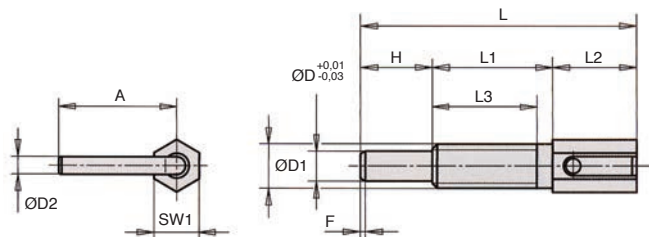

Typical application: locking

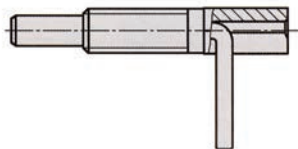

DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	H	A	SW1	Fx30°	Spring strength			Price each 1 to 5	
												initial F1 (N)	final F2 (N)	Tightening Force max (Nm)		
DIL6	4	M6	2,3	41,5	20,0	12,0	17,0	9,5	15,5	6	0,7	3	10	1,6	✓	7,95 €
DIL10	6	M10	3,5	65,0	33,5	17,5	30,0	14,0	22,9	10	1,1	4	16	10,0	✓	8,51 €
DIL12	8	M12	4,7	73,0	31,8	22,2	28,0	19,0	31,2	12	1,3	4	22	13,0	✓	9,25 €
DIL16	10	M16	4,7	102,5	50,5	27,0	44,5	25,0	32,7	16	1,6	4	23	42,0	✓	11,05 €

*Depending on availability - Dimensions in mm

Our other products



CHT

Asynchronous AC motor , 0.09kW



BABV

Ball lock pins lockable , Stainless steel



SVR20

Screwjack with travelling nut, with moving nut



CLSLCP_SS

Clevis components, short version, Stainless steel - short range



G-ECO

Eco range Spur gear, Steel C45



GE

Toggle latches, Standard



UTKswcr

Utiltrak® 3 wheels carriage



ACLRP

Wheel for aluminium profile, Integrated bearing



LRX

Linear roller slide, Rail - from 9410 to



DKN

Bellows coupling Gerwah®, from 0.4 to



AT5M AT10M

AT type timing belt per metre, AT5 Steel



NPTF30

Fixed tube carrier, Fixed Ø14 to Ø20

Complementary products



SDA

Locking bolt support bracket, Mounting holes parallel to locating bolt



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt



PITAss

Locking bolt, with T handle



DILC

Indexing plunger with cam, with cam