

# Lever operated locking bolt





## DIL

## Lift the lever to unlock


- Locking bolt
- Material: steel (class 5.8)
- Finish: blue zinc plated

### Info.

- Locking bolts can be used where lateral movement needs to be restricted
- Raising the lever unlocks the bolt

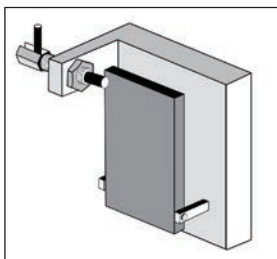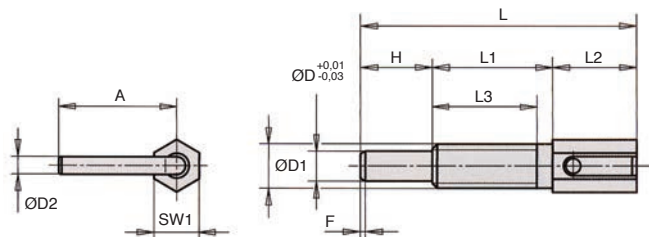

Typical application: locking

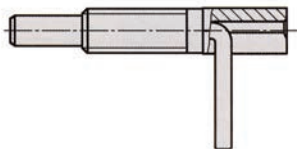

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List -10%	On request	

Part number	ØD	ØD1	ØD2	L	L1	L2	L3	H	A	SW1	Fx30°	Spring strength			Price each 1 to 5	
												initial F1 (N)	final F2 (N)	Tightening Force max (Nm)		
DIL6	4	M6	2,3	41,5	20,0	12,0	17,0	9,5	15,5	6	0,7	3	10	1,6	✓	7,95 €
DIL10	6	M10	3,5	65,0	33,5	17,5	30,0	14,0	22,9	10	1,1	4	16	10,0	✓	8,51 €
DIL12	8	M12	4,7	73,0	31,8	22,2	28,0	19,0	31,2	12	1,3	4	22	13,0	✓	9,25 €
DIL16	10	M16	4,7	102,5	50,5	27,0	44,5	25,0	32,7	16	1,6	4	23	42,0	✓	11,05 €

\*Depending on availability - Dimensions in mm

## Our other products




YG2

HEAVY DUTY spur gear, Steel 35NCD6



CHM50

 Worm and wheel gear reducer, up to 107 Nm



PTR

Idle chain sprocket, For standard applications



CLG3

Moulded plastic spur gear, Moulded plastic (nylon)




D-PAR\_SS

Stainless steel elastomount, stainless steel



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with threaded s...

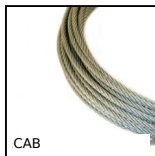

CAB

Stainless steel cable, Stainless steel



AKD

Bellows coupling Gerwah®, from 22 to 600Nm



BLOC

Doorstop, Doorstop



RBS

Dynamic washer DIN2093, Steel



BTESS

Universal stainless steel arm for tensioner, For use in



LBE

Miniature closed linear bearing, Miniature

## Complementary products



SDA

Locking bolt support bracket, Mounting holes parallel to locating bolt



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt



PITAss

Locking bolt, with T handle



DILC

Indexing plunger with cam, with cam