

Turn to unlock

DIVss

- **Material: Stainless steel**



- Locking nut supplied

Options

- Fine thread (on request)

Uses

- Locking bolts are used where the pin needs to be retracted completely
- Rotating the handle through 180° moves the pin between the two positions

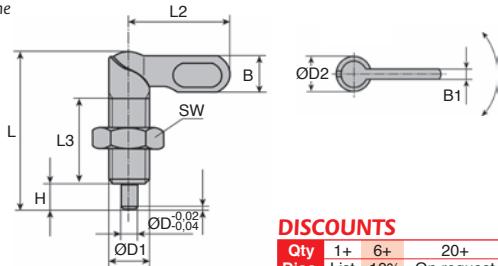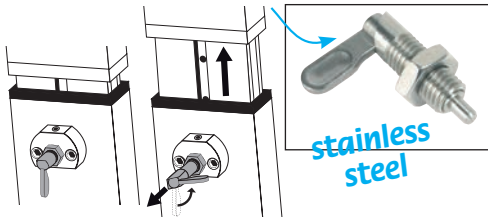

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	ØD1	ØD	ØD2	L	L2	L3	B	B1	H	SW	F _{x30°}	Spring strength		Price each 1 to 5	
												initial F(N)	final F2(N)		
DIV12-5/SS	M12	5	12	46,8	30	25	10,8	3,6	8	19	1,3	8	15	✓	22,10 €
DIV12x1.5-5/SS	M12x1.5	5	12	46,8	30	25	10,8	3,6	8	19	1,3	8	15	-	22,10 €
DIV12-6/SS	M12	6	12	46,8	30	25	10,8	3,6	8	19	1,8	8	15	✓	22,10 €
DIV12x1.5-6/SS	M12x1.5	6	12	46,8	30	25	10,8	3,6	8	19	1,8	8	15	-	22,10 €
DIV12-8/SS	M12	8	12	46,8	30	25	10,8	3,6	8	19	2,3	8	15	✓	22,10 €
DIV12x1.5-8/SS	M12x1.5	8	12	46,8	30	25	10,8	3,6	8	19	2,3	8	15	-	22,10 €
DIV16-6/SS	M16	6	16	60,4	40	32	14,4	4,8	10	24	1,8	15	35	✓	24,81 €
DIV16x1.5-6/SS	M16x1.5	6	16	60,4	40	32	14,4	4,8	10	24	1,8	15	35	-	24,81 €
DIV16-8/SS	M16	8	16	60,4	40	32	14,4	4,8	10	24	2,3	15	35	✓	24,81 €
DIV16x1.5-8/SS	M16x1.5	8	16	60,4	40	32	14,4	4,8	10	24	2,3	15	35	-	24,81 €
DIV16-10/SS	M16	10	16	60,4	40	32	14,4	4,8	10	24	2,8	15	35	✓	24,81 €
DIV16x1.5-10/SS	M16x1.5	10	16	60,4	40	32	14,4	4,8	10	24	2,8	15	35	-	24,81 €
DIV20-8/SS	M20	8	20	70,0	50	35	18,0	6,0	12	30	2,3	20	60	-	30,89 €
DIV20x1.5-8/SS	M20x1.5	8	20	70,0	50	35	18,0	6,0	12	30	2,3	20	60	-	30,89 €
DIV20-10/SS	M20	10	20	70,0	50	35	18,0	6,0	12	30	2,8	20	60	✓	30,89 €
DIV20x1.5-10/SS	M20x1.5	10	20	70,0	50	35	18,0	6,0	12	30	2,8	20	60	-	30,89 €
DIV20-12/SS	M20	12	20	70,0	50	35	18,0	6,0	12	30	3,0	20	60	✓	30,89 €
DIV20x1.5-12/SS	M20x1.5	12	20	70,0	50	35	18,0	6,0	12	30	3,0	20	60	-	30,89 €

*Depending on availability - Dimensions in mm

Our other products



HRV

V-rail guidance system, Rail with carriage



SVT5

Screwjack with travelling screw, with translating screw



PRES5HR

Manual bench press, Force up to 500kg



CHMR63

Worm and wheel gear reducer, up to 196 Nm



BHC

Socket head button screw, Stainless steel A2



GLT2-17

Telescopic drawer runners for groove mounting, Partial extension



CHNrb

Warning chain with red and white links, Steel



 
ZDB

Machined plastic bevel gear, 2:1



TCLpoche

T-Clip - Aluminium profile attachment, Pocket fastening system



R_RR

Narrow spur rack, Steel



GAL21

Conveyor wheel, Plastic



RPCtc

Wheel pivoting with central hole, Steel - Polyamide - with double br...

Complementary products



SDA

Locating bolt support bracket, Mounting holes parallel to locating b...



SDB

Locating bolt support bracket, Mounting holes at 90° to locating bolt



PITAss

Locking bolt, with T handle



PITA

Locking bolt, with T handle