

## D-KONSL

## Male mounting

- Silicone truncated cone form for applications with high hygiene requirements

- Materials:

304 stainless steel frame  
Rubber-silicone cone cylinder (Elastosil MVQ)

- Hardness 55+/-5° shoreA

- Working temperature: -30°C to +200°C

### Applications


- End stop

- Supporting foot

- Food industry (FDA compliant), pharmaceutical, medical.

**NEW!**

Stainless steel

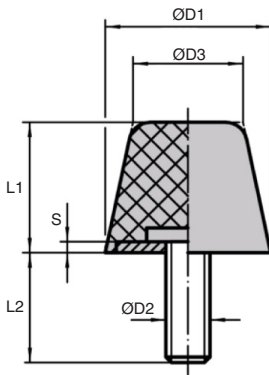

### DISCOUNTS

Qty	1+	4+	15+
Disc. Price	-5%	On request	

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Stiffness	Max.	Weight		Price each
								load (N)	Stroke	(g)	1 to 3	
D-KON5-19-16/SL	19	M5	20	12,0	16	2	63	250	4,0	10		13,05 €
D-KON6-25-20/SL	25	M6	25	16,5	20,5	2	90	460	5,1	19		13,98 €
D-KON8-32-26/SL	32	M8	30	21,0	26	2	117	760	6,5	38		15,59 €
D-KON8-38-32/SL	38	M8	30	24,5	32	2	113	900	8,0	56		31,12 €
D-KON10-50-43/SL	50	M10	40	32,0	43	2	148	1580	10,7	110		42,57 €

Dimensions in mm



# Silicone conical elast buffer

## Female mounting

## E-KONSL

- Silicone truncated cone form for applications with high hygiene requirements
- Materials:
  - 304 stainless steel frame
  - Rubber-silicone cone cylinder (Elastosil MVQ)
- Hardness 55+/-5° shoreA
- Working temperature: -30°C to +200°C


### Applications

- End stop
- Supporting foot
- Food industry (FDA compliant), pharmaceutical, medical.

**NEW!**



Stainless steel

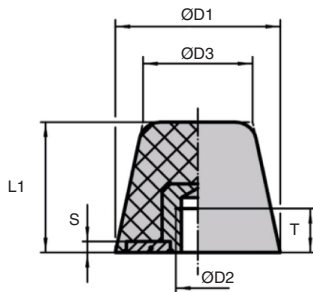

### DISCOUNTS

Qty	1+	4+	15+
Disc.	Price	-5%	On request

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Max. load (N)	Stroke	Weight (g)	Price each
E-KON5-19-16/SL	19	M5	12,0	16	2	5	63	250	4,0	7	13,49 €
E-KON6-25-20/SL	25	M6	16,5	20,5	2	6	90	460	5,1	14	14,82 €
E-KON8-32-26/SL	32	M8	21,0	26	2	8	117	760	6,5	20	16,77 €
E-KON8-38-32/SL	38	M8	24,5	32	2	8	113	900	8,0	46	32,30 €
E-KON10-50-43/SL	50	M10	32,0	43	2	10	148	1580	10,7	96	44,16 €

Dimensions in mm

## Our other products



Internal epicyclic servo reducers, from 35 to 50 Nm



Eco range Spur gear, Steel C45



Compression springs in metre length steel, by the metre



Die spring ISO10243, Heavy



AT type timing belt per metre, AT5 Steel cored polyurethane



Ball transfer unit push fit, Light



Strike for toggle latch, 15mm



Pressed steel base rigid foot, Swivelling - Ø80



Pull handle, Steel



Anti-vibration machine mount, Oval



Articulated foot Ø123, Ø 123



Stainless steel bevel gear, 2:1

## Complementary products



Silicone conical elasto buffer, Female mounting