

D-KONSL

Male mounting

- Silicone truncated cone form for applications with high hygiene requirements

- Materials:

304 stainless steel frame
Rubber-silicone cone cylinder (Elastosil MVQ)

- Hardness 55+/-5° shoreA

- Working temperature: -30°C to +200°C

Applications


- End stop

- Supporting foot

- Food industry (FDA compliant), pharmaceutical, medical.

NEW!

Stainless steel

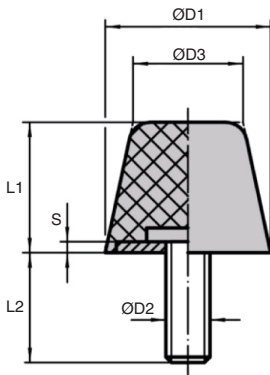

DISCOUNTS

Qty	1+	4+	15+
Disc. Price	-5%	On request	

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Stiffness	Max.	Weight		Price each
								load (N)	Stroke	(g)	1 to 3	
D-KON5-19-16/SL	19	M5	20	12,0	16	2	63	250	4,0	10		13,05 €
D-KON6-25-20/SL	25	M6	25	16,5	20,5	2	90	460	5,1	19		13,98 €
D-KON8-32-26/SL	32	M8	30	21,0	26	2	117	760	6,5	38		15,59 €
D-KON8-38-32/SL	38	M8	30	24,5	32	2	113	900	8,0	56		31,12 €
D-KON10-50-43/SL	50	M10	40	32,0	43	2	148	1580	10,7	110		42,57 €

Dimensions in mm



Silicone conical elast buffer

Female mounting

E-KONSL

- Silicone truncated cone form for applications with high hygiene requirements
- Materials:
 - 304 stainless steel frame
 - Rubber-silicone cone cylinder (Elastosil MVQ)
- Hardness 55+/-5° shoreA
- Working temperature: -30°C to +200°C


Applications

- End stop
- Supporting foot
- Food industry (FDA compliant), pharmaceutical, medical.

NEW!



Stainless steel

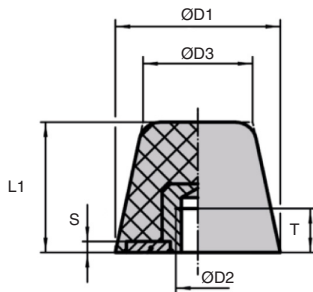

DISCOUNTS

Qty	1+	4+	15+
Disc.	Price	-5%	On request

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Stiffness Max. load (N)	Stroke	Weight (g)	Price each
E-KON5-19-16/SL	19	M5	12,0	16	2	5	63	250	4,0	7	13,49 €
E-KON6-25-20/SL	25	M6	16,5	20,5	2	6	90	460	5,1	14	14,82 €
E-KON8-32-26/SL	32	M8	21,0	26	2	8	117	760	6,5	20	16,77 €
E-KON8-38-32/SL	38	M8	24,5	32	2	8	113	900	8,0	46	32,30 €
E-KON10-50-43/SL	50	M10	32,0	43	2	10	148	1580	10,7	96	44,16 €

Dimensions in mm

Our other products



YG2
HEAVY DUTY spur gear, Steel 35NCD6




CQA30
Adjustment slide-system miniature, 30



WBGV
Lifting ring, Threaded



 GD01
Double universal joint, Standard duty



M2
Worm and wheel set, Machined plastic (delrin)



 
BPHRF
Ball transfer unit housed spring loaded, High



MHSC
Single-disc flexible coupling, Single disk




ZBconique
Machined plastic bevel gear, 1:1



RPC
Wheel, Polyamide



 NTMbr
Set screw brass tip, Brass-point



PRF-GPA
Guide for aluminium profile, Parallel rails



PMC150_M16
Anti-vibration machine mount, Square base plate

Complementary products



EKONSL
Silicone conical elasto buffer, Female mounting



D-PAR_SS
Stainless steel progressive stop, stainless steel