

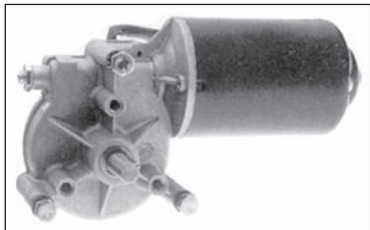


- Gearbox type: **worm and wheel**
- Bearing: self-lubricating bushes
- Angular backlash: N/A
- Max. axial load: N/A
- Max. radial load: N/A
- Working temp. from -40°C to +80°C
- Min. weight: 1.25kg
- Motor does not exhibit anti back drive behaviour for efficiencies less than 50%

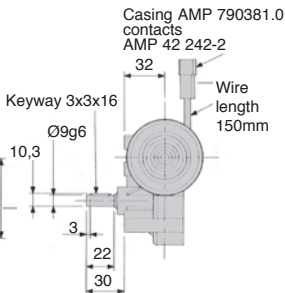

### Accessories

- Servo Amplifier **FIRSTDC-1Q-60/10**
- Speed controller **NANODC-1Q-30/3**
- Power Supplies **ALIDR60-24, ALIDR120-24**

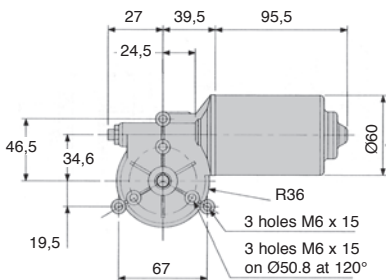

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Efficiency (%)	Unloaded speed (rpm)	Load speed (rpm)	Nominal torque (Nm)	Courant nominal (A)	Consistent card	Price each 1 to 5
<b>12 V DC Version</b>								
DOG111-12-135	12,2:1	60	135	105	1,5	4,0	No Yes	251,58 €
DOG111-12-50	62,0:1	45	50	40	5,0	5,0	No Yes	135,44 €
DOG111-12-34	62,0:1	45	34	25	6,0	4,0	No Yes	135,44 €
DOG111-12-17	62,0:1	45	17	10	6,0	2,0	Yes Yes	138,23 €
<b>12 V DC Version</b>								
DOG111-24-270	12,2:1	60	270	240	1,5	4,0	No Yes	251,58 €
DOG111-24-78	62,0:1	45	78	70	3,0	3,0	Oui Yes	149,26 €
DOG111-24-50	62,0:1	45	50	40	5,0	2,5	Yes Yes	143,73 €
DOG111-24-34	62,0:1	45	34	25	6,0	2,0	Yes Yes	138,23 €

Dimensions in mm

## Our other products



CHA138

Screwed hinge with threaded insert, 138 degrees



RDS

Safety washer Hygienic Usit®, Stainless steel



VMS

Stainless steel knurled thumb screw, Knurled



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



BCAss

Stainless steel splined bush, Inox



CHTRB

Single and dual output gearboxes, Up to 4,7 Nm



EP7

Electronic digital position indicator, 5 numbers



 
ACL-PL

Joining plate for aluminium profile, joint plate - 176x86 mm



SLB

Indexing plunger, steel class 5.8



B

Steel bevel gear, 1:1



VML

Stainless steel hexagonal headed thumb screw, Male



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard

## Complementary products



ALIDR30

12 and 24V DC power supplies, 1,5 A and 2 A



NANO

Speed controller 3A, 3 A



FIRSTDC1Q60

Speed controller 10A, 10 A



MDPOT

Potentiometer,