



Motor-gearbox 12V and 24V DC



Torque from 1.5Nm to 2Nm

DOG316

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Working temp.: -40°C to +80°C
- Weight: 1kg
- Ingress protection: IP40
- Angular backlash: N/A
- Max axial load: N/A
- Radial load: N/A

Accessories

- Servo Amplifiers **FIRSTDC-1Q-60/10** and **NANODC-1Q-30/3**
- Power Supplies **ALIDR30-12**, **ALIDR60-24**, **ALIDR-120-24**

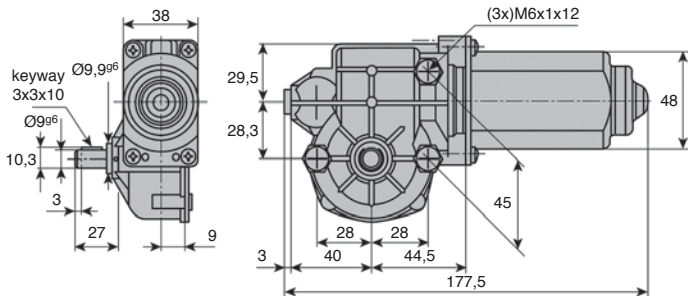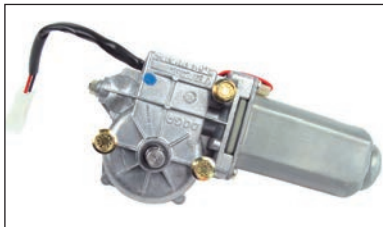

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Rendement	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (A)	Consistent card		Price each 1 to 5
						Nano	First	
12V DC Version								
DOG316-12-46	62:1	0,5	38	2,0	3,4	No	Yes	116,08 €
DOG316-12-30	62:1	0,5	32	1,5	3,0	No	Yes	116,08 €
24V DC Version								
DOG316-24-75	62:1	0,5	65	1,5	3,0	No	Yes	116,08 €
DOG316-24-46	62:1	0,5	38	2,0	1,7	Yes	Yes	116,08 €

Dimensions in mm

Our other products



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...




PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



CLSCLP

 Clevis components, short version, Steel - short range



H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



UTKpwcr

Utilitrak® 3 wheels carriage, Polymer roller carriage



ZBconique

Machined plastic bevel gear, 1:1



BH01

Single housed Bearing, Bearing fitted with adhesive



PRFRTR

Cross connector for aluminium profile, Cross connector



SSG0

Stainless steel spur gear, Stainless steel 304L



NT92

Spur gear coaxial gearbox, from 15 to 40 Nm - In-line



YG4

HEAVY DUTY spur gear, Steel 35NCD6



UCF_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel

Complementary products



ALIDRP240

24V DC power supply, 10 A



NANO

Speed controller 3A, 3 A



FIRSTDC1Q60

Speed controller 10A, 10 A



MDPOT

Potentiometer,