



# Motor-gearbox 12V and 24V DC



Torque from 1.5Nm to 2Nm

DOG316

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Working temp.: -40°C to +80°C
- Weight: 1kg
- Ingress protection: IP40
- Angular backlash: N/A
- Max axial load: N/A
- Radial load: N/A

## Accessories

- Servo Amplifiers **FIRSTDC-1Q-60/10** and **NANODC-1Q-30/3**
- Power Supplies **ALIDR30-12**, **ALIDR60-24**, **ALIDR-120-24**

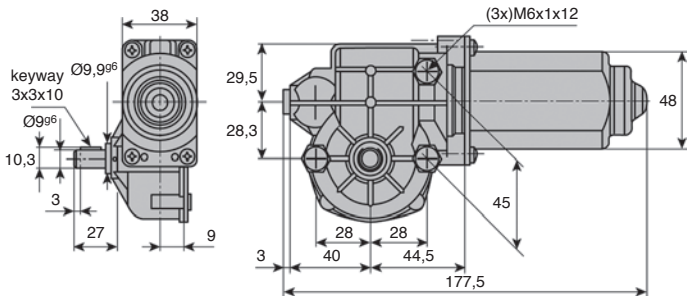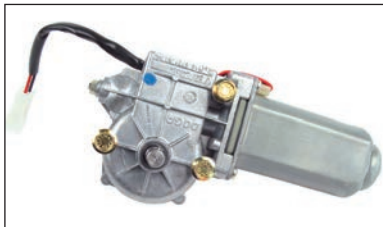

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Rendement	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (A)	Consistent card		Price each 1 to 5
						Nano	First	
<b>12V DC Version</b>								
DOG316-12-46	62:1	0,5	38	2,0	3,4	No	Yes	116,08 €
DOG316-12-30	62:1	0,5	32	1,5	3,0	No	Yes	116,08 €
<b>24V DC Version</b>								
DOG316-24-75	62:1	0,5	65	1,5	3,0	No	Yes	116,08 €
DOG316-24-46	62:1	0,5	38	2,0	1,7	Yes	Yes	116,08 €

Dimensions in mm

## Our other products



RAG  
Roller guide,



BTESS  
Universal stainless steel arm for tensioner, For use in hostile envi...



BPHF  
Ball transfer unit push fit, Heavy



M1  
Worm and wheel set, Hardened steel



BABV  
Ball lock pins lockable, Stainless steel



T25-6ECO  
T type timing pulley, Economy range - T2.5 aluminium



PRF\_PL\_9090  
Joining plate for aluminium profile, Joint plate - 90x90 mm



EPRC  
High helix leadscrew, Cylindrical nut - up to 40mm per rotation



DOMI50  
Domino 50 adjustable slide, Slide DOMILINE 50



MEFC  
Flanged sintered ferrous bush, Self-lubricating FP20



GTC  
Belt tensioner, For standard applications



M0  
Worm and wheel set, Machined plastic (delrin)

## Complementary products



FIRSTDC1Q60  
Speed controller 10A, 10 A



NANO  
Speed controller 3A, 3 A