

DOMINO rotary table



DOMIMD




 

For precise rotary positioning

- **Manually operated rotary table**
- Fast and accurate adjustment
- High position repeatability
- Principle: High-precision worm and wheel
- Fix using CHC4 screws
- Locking torque 10Nm
- Ratio: 55/1

Precise and rapid adjustment

Accessories

- **DOMI-M** mounting plate required when attaching to adjustable slides

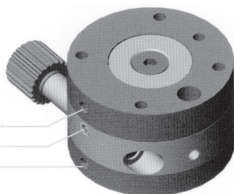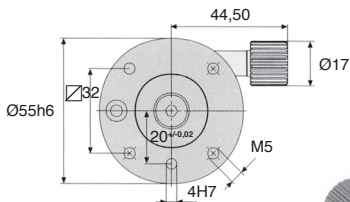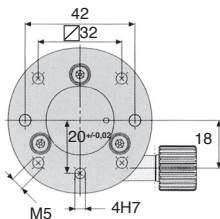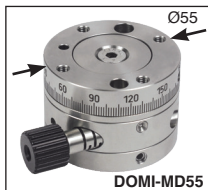

Quick-positioning screw
Lubrication hole
Locking screw

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Rotation range	Max. torque input (Nm)	Max. torque on table (Nm)	Tolerance		Weight (kg)	Price each
				Concentricity (mm)	Flatness (mm)		
DOMI-MDV55	0 to +∞	1,5	5	+/- 0,02	+/- 0,02	0,61	873,93 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



DOMINO rotary table

For precise rotary positioning



DOMIMD

- Manually operated rotary table
- Fast and accurate adjustment
- High position repeatability
- Principle: High-precision worm and wheel
- Fix using CHC4 screws
- Locking torque 10Nm
- Ratio: 40/1


Precise and rapid adjustment

Accessories

- DOMI-M mounting plate required when attaching to adjustable slides

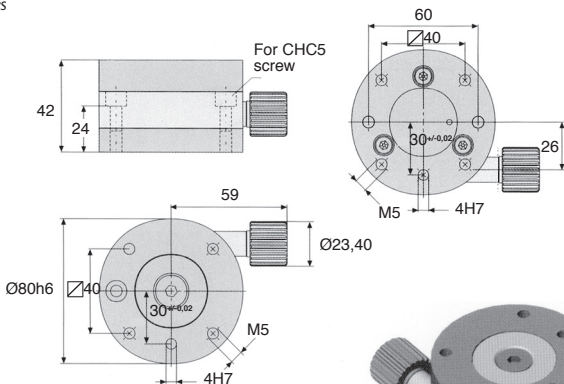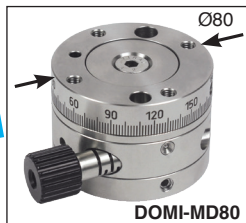

Quick-positioning screw
Lubrication hole
Locking screw

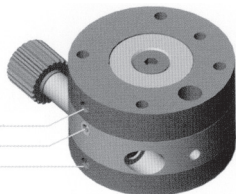

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Rotation range	Max. torque		Tolerance		Weight (kg)	Price each
		input (Nm)	on table (Nm)	Concentricity (mm)	Flatness (mm)		
DOMI-MDV80	0 to +∞	2,5	5	+/- 0,03	+/- 0,03	1,60	1 495,11 €

Dimensions in mm

Our other products



GD01

Double universal joint,
Standard duty



F7-P-AM

Multifunction display,
Magnetic band



LRR22

Small dimension latch
with locking system,
Aluminium




RPB

Ball screw bearing
unit, Support



ZG1

 Plastic spur gear,
Machined plastic
(delrin)



T2

T type timing belt,
T2.5 Steel cored
polyurethane



KH

Linear bearing, Light



COA-COG

Surface mounting
plate, Surface
mounting plate for
ball joint



BLM

Spring loaded plunger
with ball tip, Stainless
steel body



E60

Right angle helical
reducers, from 4.50 to
62 Nm



PSG05HC

Skive hobbed spur
gears - precision
range, Case hardened



PSPE22

Conical flexible shaft
handlee Ø22, Black
PVC

Complementary products



DOMI_MD

Domino rotary table,
55/1



DOMI120

Domino 120
adjustable slide, Slide
DOMILINE 120