

DOMINO rotary table



DOMIMD



For precise rotary positioning

- **Manually operated rotary table**
- Fast and accurate adjustment
- High position repeatability
- Principle: High-precision worm and wheel
- Fix using CHC4 screws
- Locking torque 10Nm
- Ratio: 55/1

Precise and rapid adjustment

Accessories

- **DOMI-M** mounting plate required when attaching to adjustable slides

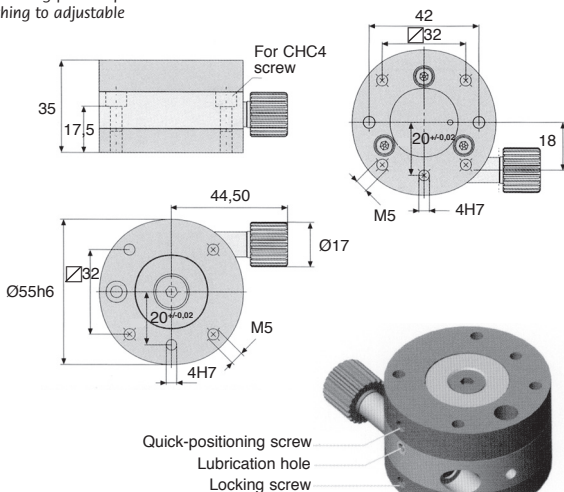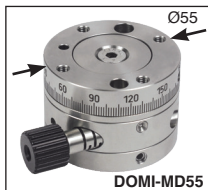

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Rotation range	Max. torque input (Nm)	Max. torque on table (Nm)	Tolerance		Weight (kg)	Price each
				Concentricity (mm)	Flatness (mm)		
DOMI-MDV55	0 to +∞	1,5	5	+/- 0,02	+/- 0,02	0,61	873,93 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



DOMINO rotary table

For precise rotary positioning



DOMIMD

- Manually operated rotary table
- Fast and accurate adjustment
- High position repeatability
- Principle: High-precision worm and wheel
- Fix using CHC4 screws
- Locking torque 10Nm
- Ratio: 40/1


Precise and rapid adjustment

Accessories

- DOMI-M mounting plate required when attaching to adjustable slides

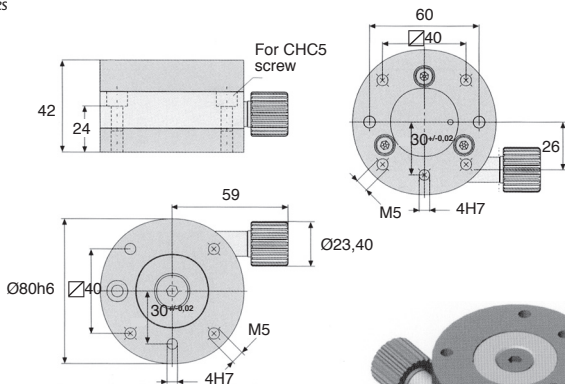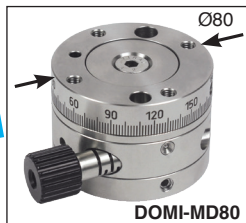

Quick-positioning screw
Lubrication hole
Locking screw

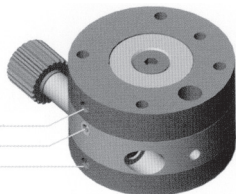

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-20%	On request

Part number	Rotation range	Max. torque		Tolerance		Weight (kg)	Price each
		input (Nm)	on table (Nm)	Concentricity (mm)	Flatness (mm)		
DOMI-MDV80	0 to +∞	2,5	5	+/- 0,03	+/- 0,03	1,60	1 495,11 €

Dimensions in mm

Our other products



NPTR10

Adjustable cross clamp, Adjustable




CHM63-MOT

Asynchronous AC motorgearboxes 0.37 to 1.5kW, 0.37 to 1.5kW




RPCplss

 Swivel castor with plate, Stainless steel - Polyamide



TPR

 High helix leadscrew, Leadscrew only - up to 40mm per rotation



BCM_HPBT

Modular cylindrical brush, PBT polyester bristles



ZDB

Machined plastic bevel gear, 2:1



BTC_M

End cap with threaded insert for square tube, With threaded insert



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



CHMR

Reaction arm, CHM and CHMR gear



MHWC

Double-disc flexible coupling, Double disk



VELM4

Screw-on base for hook-and-loop strip,



PW_PWG3

Wheel - precision range, Bronze

Complementary products



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



DOMI_MD

Domino rotary table, 40/1