

- For locking one part to another
- Relative positioning
- Material:
stainless steel 303
- Sold by the packet



DISCOUNTS

No. pack	1+	5+	10+	20+
Disc.	List	-20%	-30%	On request

Références	ØD m6	C	Longueur L	Nb. par lot	Stock*	Prix Uni. par boîte
DP0.8-10/B	0,8	0,12	10	100	✓	6,61 €
DP1.0-4/B	1,0	0,15	4	100	✓	5,79 €
DP1.0-5/B	1,0	0,15	5	100	✓	6,09 €
DP1.0-6/B	1,0	0,15	6	100	✓	6,24 €
DP1.0-8/B	1,0	0,15	8	100	✓	6,37 €
DP1.0-10/B	1,0	0,15	10	100	✓	6,61 €
DP1.0-12/B	1,0	0,15	12	100	✓	6,75 €
DP1.5-5/B	1,5	0,23	5	100	✓	6,75 €
DP1.5-6/B	1,5	0,23	6	100	✓	6,75 €
DP1.5-8/B	1,5	0,23	8	100	✓	6,93 €
DP1.5-10/B	1,5	0,23	10	100	✓	6,97 €
DP1.5-12/B	1,5	0,23	12	100	✓	7,13 €
DP1.5-14/B	1,5	0,23	14	100	✓	7,55 €
DP1.5-16/B	1,5	0,23	16	100	✓	7,80 €
DP2.0-4/B	2,0	0,30	4	100	✓	6,75 €
DP2.0-5/B	2,0	0,30	5	100	✓	6,80 €
DP2.0-6/B	2,0	0,30	6	100	✓	7,03 €
DP2.0-8/B	2,0	0,30	8	100	✓	7,30 €
DP2.0-10/B	2,0	0,30	10	100	✓	7,55 €
DP2.0-12/B	2,0	0,30	12	100	✓	8,08 €
DP2.0-14/B	2,0	0,30	14	100	✓	8,40 €
DP2.0-16/B	2,0	0,30	16	100	✓	8,80 €
DP2.0-18/B	2,0	0,30	18	100	✓	9,24 €
DP2.0-20/B	2,0	0,30	20	100	✓	10,36 €
DP2.5-6/B	2,5	0,40	6	100	✓	8,17 €
DP2.5-8/B	2,5	0,40	8	100	✓	8,76 €
DP2.5-10/B	2,5	0,40	10	100	✓	9,44 €
DP2.5-12/B	2,5	0,40	12	100	✓	9,90 €
DP2.5-16/B	2,5	0,40	16	100	✓	11,11 €
DP2.5-20/B	2,5	0,40	20	100	✓	13,03 €
DP2.5-24/B	2,5	0,40	24	100	✓	14,03 €
DP3.0-5/B	3,0	0,45	5	100	✓	9,20 €
DP3.0-6/B	3,0	0,45	6	100	✓	9,36 €
DP3.0-8/B	3,0	0,45	8	100	✓	9,90 €
DP3.0-10/B	3,0	0,45	10	100	✓	10,36 €
DP3.0-12/B	3,0	0,45	12	100	✓	10,58 €

*Depending on availability - Dimensions in mm

Références	ØD m6	C	Longueur L	Nb. par lot	Stock*	Prix Uni. par boîte
DP3.0-14/B	3,0	0,45	14	100	✓	11,67 €
DP3.0-16/B	3,0	0,45	16	100	✓	12,21 €
DP3.0-18/B	3,0	0,45	18	100	✓	12,69 €
DP3.0-20/B	3,0	0,45	20	100	✓	13,35 €
DP3.0-24/B	3,0	0,45	24	100	✓	14,45 €
DP3.0-30/B	3,0	0,45	30	100	✓	21,57 €
DP4.0-6/B	4,0	0,60	6	100	✓	12,39 €
DP4.0-8/B	4,0	0,60	8	100	✓	13,26 €
DP4.0-10/B	4,0	0,60	10	100	✓	14,45 €
DP4.0-12/B	4,0	0,60	12	100	✓	14,24 €
DP4.0-14/B	4,0	0,60	14	100	✓	15,79 €
DP4.0-16/B	4,0	0,60	16	100	✓	16,56 €
DP4.0-18/B	4,0	0,60	18	100	✓	18,48 €
DP4.0-20/B	4,0	0,60	20	100	✓	19,71 €
DP4.0-24/B	4,0	0,60	24	100	✓	22,97 €
DP4.0-40/B	4,0	0,60	40	100	✓	33,87 €
DP4.0-50/B	4,0	0,60	50	100	✓	43,72 €
DP5.0-10/B	5,0	0,75	10	25	✓	5,34 €
DP5.0-12/B	5,0	0,75	12	25	✓	5,79 €
DP5.0-14/B	5,0	0,75	14	25	✓	6,37 €
DP5.0-16/B	5,0	0,75	16	25	✓	6,75 €
DP5.0-20/B	5,0	0,75	20	25	✓	8,02 €
DP5.0-24/B	5,0	0,75	24	25	✓	8,92 €
DP5.0-30/B	5,0	0,75	30	25	✓	9,90 €
DP5.0-40/B	5,0	0,75	40	25	✓	12,39 €
DP5.0-50/B	5,0	0,75	50	25	✓	15,97 €
DP6.0-10/B	6,0	0,90	10	25	✓	7,23 €
DP6.0-12/B	6,0	0,90	12	25	✓	7,80 €
DP6.0-14/B	6,0	0,90	14	25	✓	8,40 €
DP6.0-16/B	6,0	0,90	16	25	✓	9,05 €
DP6.0-20/B	6,0	0,90	20	25	✓	10,58 €
DP6.0-24/B	6,0	0,90	24	25	✓	11,49 €
DP6.0-28/B	6,0	0,90	28	25	✓	12,97 €
DP6.0-30/B	6,0	0,90	30	25	✓	13,65 €
DP6.0-40/B	6,0	0,90	40	25	✓	16,99 €
DP6.0-45/B	6,0	0,90	45	25	✓	21,75 €
DP8.0-14/B	8,0	1,20	14	25	✓	14,64 €
DP8.0-16/B	8,0	1,20	16	25	✓	15,57 €
DP8.0-20/B	8,0	1,20	20	25	✓	17,54 €
DP8.0-24/B	8,0	1,20	24	25	✓	19,04 €
DP8.0-30/B	8,0	1,20	30	25	✓	21,75 €
DP8.0-40/B	8,0	1,20	40	25	✓	26,45 €
DP8.0-50/B	8,0	1,20	50	25	✓	31,28 €
DP10.0-20/B	10,0	1,50	20	25	✓	72,56 €
DP10.0-40/B	10,0	1,50	40	25	✓	39,45 €
DP10.0-50/B	10,0	1,50	50	25	✓	47,56 €


*Depending on availability - Dimensions in mm

Our other products




HK

Manual locking clamp,
Manual locking clamp
LRX

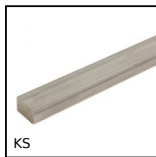

KS

Keysteel, Stainless
steel - Keystock

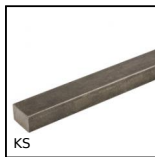

KS

Keysteel, Steel -
Keystock



PTA100

Articulated levelling
foot, pressed base
Ø100, Ø 100




J53

Spur gear coaxial
gearbox, from 0.43 to
1.15 - Inline



TBE16

 Economic mini-table
with trapezoidal
leadscrew, 5kg



JFM

Flanged polymer
bush, Universal
polymer



PRF4590_E

Bracket for aluminium
profile, PRF4590



SLBS

Stainless steel
indexing plunger,



UCF_PBT

Stainless
steel/Polymer flanged



VTHA

Magnetic screw with
hexagonal head, Steel



MRA_SS

Stainless steel Quick
link, Stainless steel

Complementary products



SRP

Slotted spring pin
ISO8752, Split ISO
8752



DHX

Dowel pin internal
thread, Extractable
DIN 7979D



DH

Dowel pin, Solid DIN
6325