


## D-PAR D-KON

## Male mounting


- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Materials  
core: Steel plates cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

### Uses

- Shock-absorbing stop

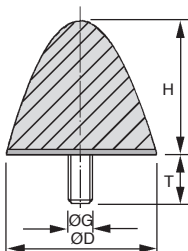

Type D-PAR

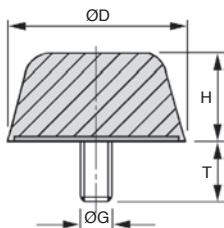

Type D-KON



### DISCOUNTS A

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

### DISCOUNTS B

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

 
Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24	M6	18	20	24	✓	A 2,64 €
D-PAR8-30-36	M8	20	30	36	✓	A 3,42 €
D-PAR8-35-40	M8	20	35	40	✓	A 5,11 €
D-PAR8-50-67	M8	36	50	67	✓	A 10,56 €
D-PAR10-50-58	M10	28	50	58	✓	A 9,30 €
D-PAR12-75-89	M12	37	75	89	✓	B 13,57 €
D-PAR16-115-136	M16	43	115	136	-	B 52,00 €
D-KON6-25-17	M6	18	25	17	-	B 2,47 €
D-KON10-50-18	M10	28	50	18	✓	A 7,00 €
D-KON12-80-30	M12	35	80	30	✓	B 17,47 €
D-KON16-125-45	M16	45	125	45	-	B 29,18 €

\*Depending on availability - Dimensions in mm

## Our other products



RT25ss  
Self-centering flanged locking assembly, Medium/high torque



SLS  
Bearing block for leadscrew, Fixed Drylin® bearing block



ZHBRA  
Plastic bevel gear, 1,25:1 2:1 3:1



CLM  
Male clevis end, Stainless steel short




PHG05  
Parallel axis helical gear - Precision range, 20NCD2 case hardened s...



BPL  
Ball transfer unit light duty, Light



TIFss  
Threaded stud - DIN976A, Stainless steel

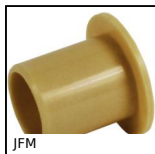

JFM  
Flanged polymer bush, Universal polymer



PAT123  
Pressed stainless steel articulating foot



DHX  
Dowel pin internal thread, Extractable



DP  
Dowel pin, Solid ISO 2338



CHM40  
Worm and wheel gear reducer, up to 57 Nm

## Complementary products



D-PAR\_SS  
Stainless steel elasto mount, stainless steel



DPAR\_DKON  
Conical elasto buffer, Steel



MC  
Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA  
Adjustable shock-absorber, Adjustable