


D-PAR D-KON

Male mounting


- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Materials
core: Steel plates cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop

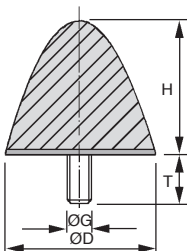

Type D-PAR

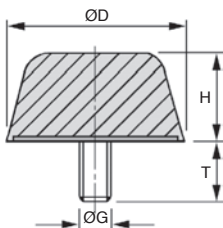

Type D-KON



DISCOUNTS A

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS B

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request


Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24	M6	18	20	24	✓	A 2,64 €
D-PAR8-30-36	M8	20	30	36	✓	A 3,42 €
D-PAR8-35-40	M8	20	35	40	✓	A 5,11 €
D-PAR8-50-67	M8	36	50	67	✓	A 10,56 €
D-PAR10-50-58	M10	28	50	58	✓	A 9,30 €
D-PAR12-75-89	M12	37	75	89	✓	B 13,57 €
D-PAR16-115-136	M16	43	115	136	-	B 52,00 €
D-KON6-25-17	M6	18	25	17	-	B 2,47 €
D-KON10-50-18	M10	28	50	18	✓	A 7,00 €
D-KON12-80-30	M12	35	80	30	✓	B 17,47 €
D-KON16-125-45	M16	45	125	45	-	B 29,18 €

*Depending on availability - Dimensions in mm

Our other products



 SVR20
Screwjack with travelling nut, with moving nut



PB
Plastic deep groove ball bearing, Plastic-glass balls material



BG
Oldham coupling, With set screw



T10-BAR
T type tooth bar stock, T10



BPH
Ball transfer unit plain fit, High



PSG125S
Spur gear - precision range, Stainless steel 316



DKGS
Backlash free coupling Gerwah®, from 0.5 to 3Nm



BABreglable
Adjustable ball pin hardened stainless steel, adjustable



NTM
Nylon tipped set screw, Nylon-point



PSG08S
Spur gear - precision range, Stainless steel 303



TOL
Swivel head, Long



AT5P_AT10P
Connecting plate for AT type timing belts, AT10

Complementary products



D-PAR_SS
Stainless steel elasto mount, stainless steel



D-PAR_DKON
Conical elasto buffer, Steel



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA
Adjustable shock-absorber, Adjustable