


D-PAR D-KON

Male mounting


- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Materials
core: Steel plates cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop

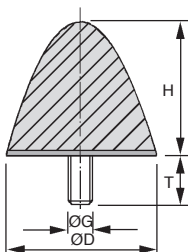

Type D-PAR

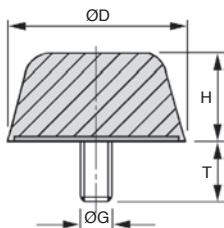

Type D-KON



DISCOUNTS A

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS B

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	T	ØD	H	Stock*	Price each 1 to 5
D-PAR6-20-24	M6	18	20	24	✓	A 2,64 €
D-PAR8-30-36	M8	20	30	36	✓	A 3,42 €
D-PAR8-35-40	M8	20	35	40	✓	A 5,11 €
D-PAR8-50-67	M8	36	50	67	✓	A 10,56 €
D-PAR10-50-58	M10	28	50	58	✓	A 9,30 €
D-PAR12-75-89	M12	37	75	89	✓	B 13,57 €
D-PAR16-115-136	M16	43	115	136	-	B 52,00 €
D-KON6-25-17	M6	18	25	17	-	B 2,47 €
D-KON10-50-18	M10	28	50	18	✓	A 7,00 €
D-KON12-80-30	M12	35	80	30	✓	B 17,47 €
D-KON16-125-45	M16	45	125	45	-	B 29,18 €

*Depending on availability - Dimensions in mm

Our other products



CHAE4060PA
Decorative asymmetric screwed hinge, Polyamide



PW_PWG1
Worm - precision range, Stainless steel



BZY
Cylindrical elasto mount, Steel



BAG-MISS
Split shaft collar with clamp lever, Stainless steel



SUP
Self-centering clamping hub steel, Without locknut



DOG316
Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



SDG_SS
Universal adjustable guide support bracket, Stainless steel



BH01
Single housed bearing, Bearing fitted with adhesive




PF55
Worm and wheel gear reducer, up to 57 Nm



HBM
Adjustment bushing for half-rail guide, Adjustment bushing



MAX26
Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm

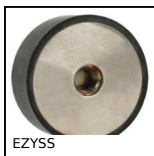

EZYSS
Stainless steel cylindrical stop, stainless steel

Complementary products



D-PAR_SS
Stainless steel elasto mount, stainless steel



DPAR_DKON
Progressive stop, Steel



DZY
Cylindrical stop, Steel



MC
Self-compensating shock-absorber, Self-compensating - without adjust...