




- The flexible rack should be used with a 20 tooth gear from the same module (see ZGDR gears)
- Length 2000mm (+/- 10mm)
- Minimum radius of curvature: 150mm
- Pressure angle 20°
- Datum reference: bottom surface

Accessories


- Rack clamp **SRS**
- Rack guide rail **ARL**
- Gear **ZGDR**

Info.

- Plastic racks are less accurate than metal racks and should not be used where accurate positioning is required.

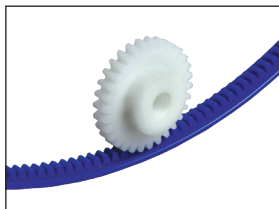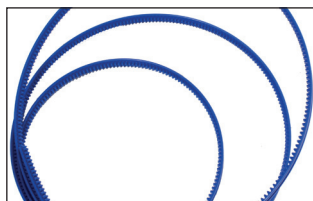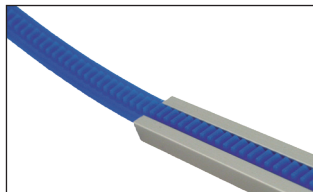

Typical application with a ZGDR gear

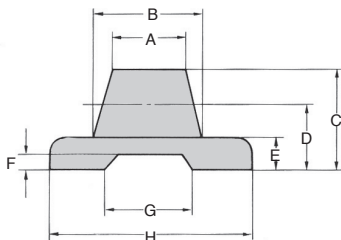


DISCOUNTS

Qty	1+	3+	6+
Disc.	List -10%	On request	

Part number	Module	Length (mm)	A	B	C	D	E	F	G	H	Allowable bending strength (N)	Weight (kg)	Price each 1 to 2
DR0.8-2000	0,8	2000	3	3,8	3,3	2,5	1,5	0,7	3,7	8	111,8	0,10	97,42 €
DR1-2000	1,0	2000	4	5,0	4,3	3,3	2,0	0,9	4,9	10	160,9	0,15	125,87 €
DR1.5-2000	1,5	2000	5	6,5	5,7	4,2	2,3	1,0	8,0	12	161,4	0,20	158,44 €
DR2-2000	2,0	2000	6	6,0	7,0	5,0	2,5	1,1	10,1	15	264,9	0,30	190,91 €

Dimensions in mm

 Our other products



Modular cylindrical brush, PBT polyester bristles



Linear bearing, Precision - steel



Hypoid gearbox - Stainless steel, up to 200 Nm



Connecting link for single chain, Steel



Ball pin, Hardened stainless steel



 
Moulded plastic bevel gear (blue nylon), 1:1



Piano hinge, Aluminium



Linear bearing, Precision - steel



Magnetic label, Flexible magnet



Articulated fixable foot with pressed base, Ø 100



Manual gearbox, Hexagonal ended handle



Accessories for PRES-3HR and PRES-4HR presses, Tool holder

Complementary products



Plastic flexible rack, Rack fixing rail