


Module 0.25-0.8

Stainless steel

- Pressure angle 20°
- Material:
Stainless steel (303) Z10CNF18.09

Options

- Alternative number of teeth
- Alternative materials (delrin, stainless steel..)
- Other lengths and diameters

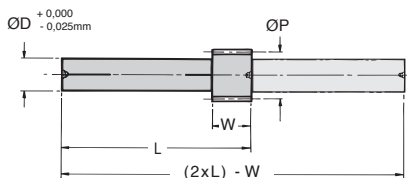

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Module	Z Teeth	ØP	L	W	ØD	Price each 1 to 5
DST0.25-15	0,25	15	3,75	20	2,50	3	55,52 €
DST0.25-18	0,25	18	4,50	20	2,50	3	57,20 €
DST0.3-16	0,3	16	4,80	20	2,50	3	55,52 €
DST0.3-20	0,3	20	6,00	20	2,50	3	57,20 €
DST0.4-18	0,4	18	7,20	25	3,00	5	57,43 €
DST0.4-27	0,4	27	10,80	25	3,00	5	58,11 €
DST0.5-16	0,5	16	8,00	25	3,00	6	60,39 €
DST0.5-20	0,5	20	10,00	25	3,00	6	62,01 €
DST0.5-24	0,5	24	12,00	25	3,00	6	64,42 €
DST0.8-15	0,8	15	12,00	32	5,00	8	67,23 €
DST0.8-16	0,8	16	12,80	32	5,00	8	67,49 €
DST0.8-18	0,8	18	14,40	32	5,00	8	71,86 €


Dimensions in mm

Stainless steel

- Pressure angle 20°
- Material:
Stainless steel (303) Z10CNF18.09

Options

- Alternative number of teeth
- Alternative materials (delrin, stainless steel..)
- Other lengths and diameters

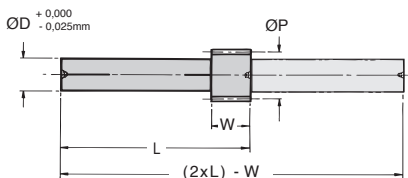

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Module	Z Teeth	ØP	L	W	ØD	Price each 1 to 5
DST1-14	1	14	14,00	38	8	10	81,47 €
DST1-16	1	16	16,00	38	8	10	83,18 €
DST1-20	1	20	20,00	38	8	10	86,79 €
DST1.25-12	1,25	12	15,00	50	10	12	110,44 €
DST1.25-15	1,25	15	18,75	50	10	12	111,79 €
DST1.25-18	1,25	18	22,50	50	10	12	121,50 €
DST1.5-13	1,5	13	19,50	76	12	15	129,69 €
DST1.5-16	1,5	16	24,00	76	12	15	131,47 €
DST1.5-20	1,5	20	30,00	76	12	15	134,02 €
DST2-13	2	13	26,00	76	20	20	137,12 €
DST2-16	2	16	32,00	76	20	20	146,40 €
DST2-18	2	18	36,00	76	20	20	157,59 €

Dimensions in mm

Our other products



HBM
Half-rail guide,
Adjustment bushing



OP3_14_06
Numerical counter
accessories,
Reduction socket



PRF_PGN
Doorstop and handle,
Handle with lock
suitable



BPHT
Ball transfer unit,
Heavy



CF
Cam follower,
Standard - steel



HTD5M_15
HTD-type pulley for
RPP-type belt, HTD5
Aluminium



 
GP
Spring loaded toggle
latch, With padlock-
holder



AKD
Bellows coupling
Gerwah®, from 22 to
600Nm



CHAuss
Front hinge, 270°



BOX-TOR-TOOL
Box set of Nitrile O-
rings, Extraction tools



EFTC
Structural fixing
support, Stainless
steel



ATZYSS
Anti vibration mount,
Stainless steel

Complementary products



DT
Pinion shaft, Steel
20NCD2



PPS05
Pinion shaft -
precision range,
Stainless steel