

Chain idler sprocket



Steel or plastic

DTR

- **Disk shaped idler sprocket**
- Bearing incorporated
- Lubricated for life
- Materials:
 - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
 - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C

Info

- For use with **SBR** chains

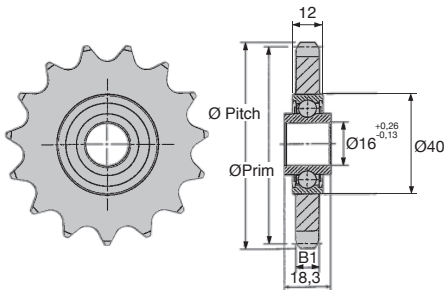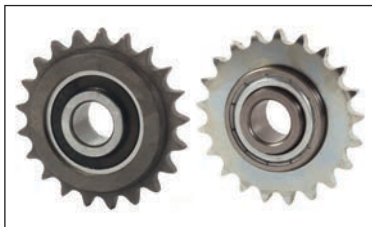


DISCOUNTS

| | | | | |
|------------|-----|------|------------|-----|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. List | -5% | -10% | On request | |

| Part number | Pitch | Standard | N° of teeth | ØPitch | ØPrim | B1 | Bearing | Unit price 1 to 9 |
|----------------|--------|----------|-------------|--------|-------|-------|---------|-------------------|
| Steel | | | | | | | | |
| DTR-06B1-21 | 9,525 | 06B1 | 21 | 68,00 | 63,90 | 5,30 | 203KRR | 11,65 € |
| DTR-08B1-16 | 12,7 | 08B1 | 16 | 69,50 | 65,10 | 7,20 | 203KRR | 12,30 € |
| DTR-10B1-15 | 15,875 | 10B1 | 15 | 83,00 | 76,36 | 9,10 | 203KRR | 14,61 € |
| DTR-12B1-13 | 19,05 | 12B1 | 13 | 87,50 | 79,59 | 11,10 | 203KRR | 15,85 € |
| DTR-12B1-15 | 19,05 | 12B1 | 15 | 99,80 | 91,63 | 11,10 | 203KRR | 17,21 € |
| Plastic | | | | | | | | |
| DTR-06B1-21/Z | 9,525 | 06B1 | 21 | 68,00 | 63,90 | 5,30 | 203KRR | 17,80 € |
| DTR-08B1-16/Z | 12,7 | 08B1 | 16 | 69,50 | 65,10 | 7,20 | 203KRR | 18,51 € |
| DTR-10B1-15/Z | 15,875 | 10B1 | 15 | 83,00 | 76,36 | 9,10 | 203KRR | 19,47 € |
| DTR-12B1-13/Z | 19,05 | 12B1 | 13 | 87,50 | 79,59 | 11,10 | 203KRR | 21,21 € |
| DTR-12B1-15/Z | 19,05 | 12B1 | 15 | 99,80 | 91,63 | 11,10 | 203KRR | 22,88 € |

Dimensions in mm

 Our other products



CAB

Galvanised steel cable, Galvanised steel



F7-SF-SM

Multifunction display, Right angled mounting bracket



PRES4HR

Manual workbench press, Force up to 600kg



PV2R

Adjustable suction-cup support, Increased grip



 
RUR

Wheel, Polyurethane - Aluminium rim (Free running)



PW_PWG2

Wheel - precision range, Bronze



TBV

Manual lifting tables, 12kg



WSRM

Cylindrical polymer nut, Polymer (Iglidur®) - 1 thread



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50



G1

Steel spur gear, Steel 20NCD2



H02SS

Needle roller universal joint - Stainless steel, Heavy duty



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm

Complementary products



SUA4

Single chain supplied by the metre, Steel