


- **Disk shaped idler sprocket**
- Integrated bearing
- Lubricated for life
- Materials:
  - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
  - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C

### Accessories

- For use with **SBR** chains (tome 4 p.122)

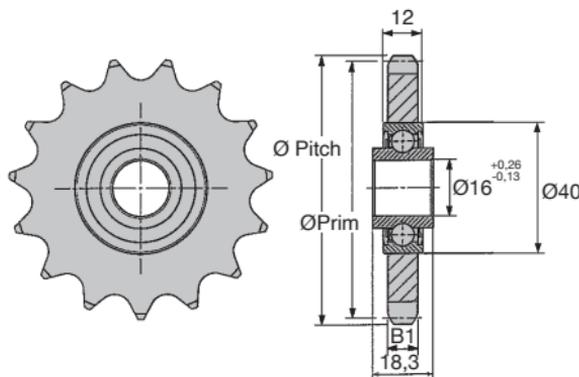

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Pitch	Standard	N° of teeth	ØPitch	ØPrim	B1	Bearing	Stock*	Price each
									1 to 9
<b>Steel</b>									
DTR-06B1-21	9,525	06B1	21	68,00	63,90	5,30	203KRR	✓	12,98 €
DTR-08B1-16	12,7	08B1	16	69,50	65,10	7,20	203KRR	✓	13,72 €
DTR-10B1-15	15,875	10B1	15	83,00	76,36	9,10	203KRR	✓	16,28 €
DTR-12B1-13	19,05	12B1	13	87,50	79,59	11,10	203KRR	-	17,67 €
DTR-12B1-15	19,05	12B1	15	99,80	91,63	11,10	203KRR	✓	19,20 €
<b>Plastic</b>									
DTR-06B1-21/Z	9,525	06B1	21	68,00	63,90	5,30	203KRR	-	19,83 €
DTR-08B1-16/Z	12,7	08B1	16	69,50	65,10	7,20	203KRR	-	20,65 €
DTR-10B1-15/Z	15,875	10B1	15	83,00	76,36	9,10	203KRR	-	21,70 €
DTR-12B1-13/Z	19,05	12B1	13	87,50	79,59	11,10	203KRR	-	23,67 €
DTR-12B1-15/Z	19,05	12B1	15	99,80	91,63	11,10	203KRR	-	25,50 €

\*Depending on availability - Dimensions in mm

# Idler chain sprocket



## PTR

## For standard applications


- Chain sprocket for use with the BTE universal tension arm
- With ball bearings
- Greased for life
- Material: nut, screw, and sprocket in bichromate steel
- Max speed: 70 rpm
- t° of use: -30°C to + 80°C

**Good price/  
quality/ratio**



### Accessories

- BTE tension arm (tome 4 p.142)

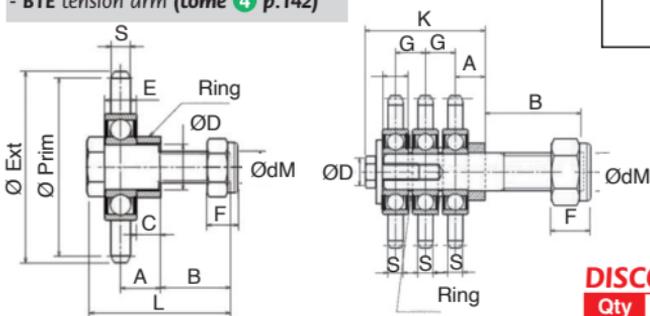

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	

Part number	Pitch	No. of teeth Z	S	ØdM	ØD	A	B	C	E	F	L	Arm size	Stock*	Price
														each 1 to 3
<b>Single chain</b>														
PTR-04B1	6,000	15	2,6	M6	6	7	15	4	6	6	28	BTE2	✓	27,55 €
PTR-05B1	8,000	14	2,8	M8	8	7,5	16	4	7	8	30	BTE2	✓	25,11 €
PTR-06B1	9,525	17	5,3	M10	12	12	22	7	10	10	44	BTE3	✓	17,50 €
PTR-08B1	12,700	17	7,2	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	19,33 €
PTR-10B1	15,800	16	9,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	25,09 €
PTR-12B1	19,050	14	11,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	28,84 €

Part number	Pitch	No. of teeth Z	ØdM	ØD	A	B	G	F	L	Arm size	Stock*	Price
												each 1 to 3
<b>Double chain</b>												
PTR-06B2	9,525	17	M12	12	12	35	10,24	12	35	BTE4	-	42,61 €
PTR-08B2	12,700	17	M18	17	15	45	13,92	18,5	44	BTE5	-	50,12 €
PTR-10B2	15,800	16	M20	17	15	45	16,59	20	46	BTE6	-	72,71 €
PTR-12B2	19,050	14	M20	17	15	45	19,46	20	49	BTE6	-	82,72 €
<b>Triple chain</b>												
PTR-06B3	9,525	17	M12	12	12	35	10,24	12	45	BTE4	-	57,67 €
PTR-08B3	12,700	17	M18	17	15	45	13,92	18,5	58	BTE5	-	75,22 €
PTR-10B3	15,800	16	M20	17	15	45	16,59	20	64	BTE6	-	107,82 €
PTR-12B3	19,050	14	M20	17	15	45	19,46	20	64	BTE6	-	112,86 €

\*Depending on availability - Dimensions in mm



# Stainless steel idler chain sprocket


For hostile environments

PTRss

- Idler chain sprocket for use with BTE/SS universal tension arm
- Fitted with sealed stainless steel bearings
- Max working temperature: 100°C
- Max speed : 70 rpm
- Material :Axle and gear :  
Stainless steel 304L  
Nuts : Stainless steel A2

## Accessories

- BTE/SS tension arm (tome 4 p.143)

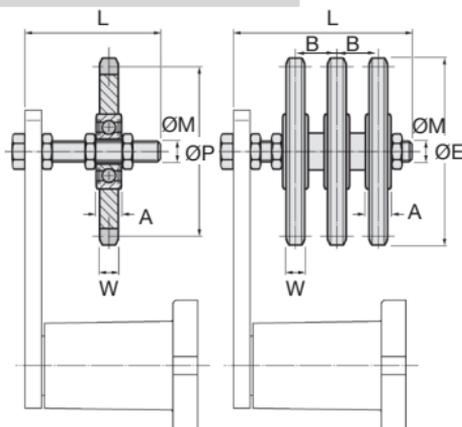

**✓ IN STOCK\***  
Otherwise contact us

## DISCOUNTS

Qty	1+	3+	5+
Disc.	List	-10%	On request

Part number	Pitch	N° of teeth Z	W	ØM	A	B	L	ØP	ØE	Size of arm	Price each 1 to 2
<b>Simple</b>											
PTR-06B1/SS	9,525	15	5,3	M10	9	-	55	45,81	49,3	BTE3/BTE4	42,72 €
PTR-08B1/SS	12,700	15	7,2	M10	9	-	55	61,09	65,5	BTE4	52,60 €
PTR-10B1/SS	15,800	15	9,1	M12	12	-	80	76,36	83,0	BTE5	67,55 €
PTR-12B1/SS	19,050	15	11,1	M12	12	-	80	91,63	99,8	BTE5	100,47 €
<b>Double</b>											
PTR-06B2/SS	9,525	15	5,3	M10	9	10,24	55	45,81	49,3	BTE4	78,64 €
PTR-08B2/SS	12,700	15	7,2	M10	9	13,92	60	61,09	65,5	BTE4	98,37 €
PTR-10B2/SS	15,800	15	9,1	M12	12	16,59	80	76,36	83,0	BTE5	127,09 €
PTR-12B2/SS	19,050	15	11,1	M12	12	19,46	80	91,63	99,8	BTE5	193,49 €
<b>Triple</b>											
PTR-06B3/SS	9,525	15	5,3	M10	9	10,24	60	45,81	49,3	BTE4	95,51 €
PTR-08B3/SS	12,700	15	7,2	M12	9	13,92	80	61,09	65,5	BTE5	137,11 €
PTR-10B3/SS	15,800	15	9,1	M12	12	16,59	80	76,36	83,0	BTE5	174,04 €
PTR-12B3/SS	19,050	15	11,1	M20	15	19,46	120	91,63	99,8	BTE6	228,81 €

\*Depending on availability - Dimensions in mm