

Chain idler sprocket



Steel or plastic

DTR

- **Disk shaped idler sprocket**
- Bearing incorporated
- Lubricated for life
- Materials:
 - Sprocket in XC38 zinc plated steel or PA6 polyamide (30% glass fibre)
 - Steel bearing
- Max speed 70m/min
- Working temp -30/+80°C

Info

- For use with **SBR** chains

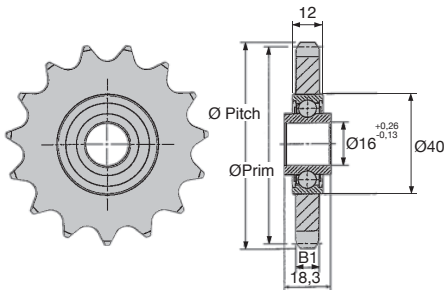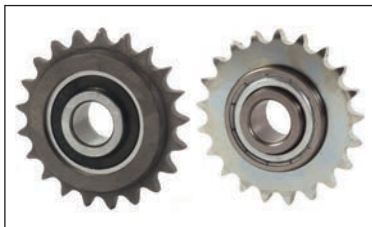

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Pitch	Standard	N° of teeth	ØPitch	ØPrim	B1	Bearing	Unit price 1 to 9
Steel								
DTR-06B1-21	9,525	06B1	21	68,00	63,90	5,30	203KRR	11,65 €
DTR-08B1-16	12,7	08B1	16	69,50	65,10	7,20	203KRR	12,30 €
DTR-10B1-15	15,875	10B1	15	83,00	76,36	9,10	203KRR	14,61 €
DTR-12B1-13	19,05	12B1	13	87,50	79,59	11,10	203KRR	15,85 €
DTR-12B1-15	19,05	12B1	15	99,80	91,63	11,10	203KRR	17,21 €
Plastic								
DTR-06B1-21/Z	9,525	06B1	21	68,00	63,90	5,30	203KRR	17,80 €
DTR-08B1-16/Z	12,7	08B1	16	69,50	65,10	7,20	203KRR	18,51 €
DTR-10B1-15/Z	15,875	10B1	15	83,00	76,36	9,10	203KRR	19,47 €
DTR-12B1-13/Z	19,05	12B1	13	87,50	79,59	11,10	203KRR	21,21 €
DTR-12B1-15/Z	19,05	12B1	15	99,80	91,63	11,10	203KRR	22,88 €

Dimensions in mm

Our other products



Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



Plastic sprocket,
12.7mm (DIN 08B-1)



Steel Clamping collar,
Steel



Precision locknut,
Precision locknut



Ground spur gear,
Heat treated steel



Flanged sintered
ferrous bush, Self-
lubricating FP20
ferrous alloy M...



High Temperature
wheel, up to 200kg



 
Parallel axis helical
gear, Machined plastic
(delrin)



Ballscrew bearing
unit, Support



Right angled bracket
for aluminium profile,
4 holes



Worm and wheel set,
Machined plastic
(delrin)



Fixed castor with
plate, Steel -
Polyamide

Complementary products



Single chain supplied
by the metre, Steel