



- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Progressive absorption of energy
- Materials
 - core: Steel plates
 - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop

Info.

- **Not sold individually, please contact us for details**
- Values for loads and rigidity are given as a guide only

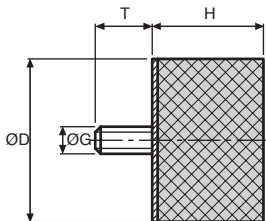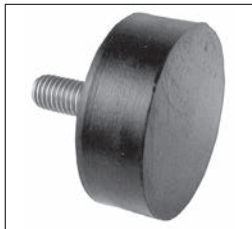

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)		
D-ZY4-10-10	M4	10	10	10	38	43	✓	A 1,16 €
D-ZY4-15-8	M4	15	8	10	122	95	✓	A 1,25 €
D-ZY4-15-10	M4	15	10	10	106	95	✓	A 1,42 €
D-ZY4-15-15	M4	15	15	10	74	95	✓	A 1,58 €
D-ZY6-20-15	M6	20	15	18	138	170	✓	A 1,77 €
D-ZY6-20-20	M6	20	20	18	-	-	✓	A 1,97 €
D-ZY6-20-25	M6	20	25	18	-	-	✓	A 1,97 €
D-ZY6-25-10	M6	25	10	18	-	-	✓	A 1,85 €
D-ZY6-25-15	M6	25	15	18	254	280	✓	A 2,04 €
D-ZY6-25-20	M6	25	20	18	128	280	✓	A 2,29 €
D-ZY6-25-25	M6	25	25	18	-	-	✓	A 2,47 €
D-ZY6-25-30	M6	25	30	18	80	280	✓	A 2,75 €
D-ZY8-30-20	M8	30	20	20	200	400	✓	A 3,07 €
D-ZY8-30-25	M8	30	25	20	-	-	✓	A 3,42 €
D-ZY8-30-30	M8	30	30	20	120	400	✓	A 3,87 €
D-ZY8-30-40	M8	30	40	20	-	-	✓	A 4,48 €
D-ZY8-40-20	M8	40	20	23	-	-	✓	A 4,21 €
D-ZY8-40-30	M8	40	30	23	23	234	✓	A 4,76 €
D-ZY8-40-40	M8	40	40	23	-	-	✓	A 5,00 €
D-ZY10-40-30	M10	40	30	28	-	-	✓	A 4,76 €
D-ZY10-50-20	M10	50	20	28	680	1000	✓	A 6,39 €
D-ZY10-50-30	M10	50	30	28	425	1000	✓	A 6,58 €
D-ZY10-50-40	M10	50	40	28	-	-	✓	A 7,22 €
D-ZY10-50-45	M10	50	45	28	-	-	-	A 7,63 €
D-ZY10-50-50	M10	50	50	28	-	-	✓	A 8,53 €
D-ZY10-60-40	M10	60	40	28	-	-	✓	A 12,58 €
D-ZY10-70-45	M10	70	45	28	-	-	-	A 16,27 €
D-ZY12-60-40	M12	60	40	33	-	-	✓	B 7,35 €
D-ZY12-75-25	M12	75	25	37	2000	2300	✓	B 6,98 €
D-ZY12-75-40	M12	75	40	37	810	2300	✓	B 10,53 €
D-ZY12-75-50	M12	75	50	37	-	-	-	B 10,97 €
D-ZY12-75-55	M12	75	55	37	-	-	✓	B 11,59 €
D-ZY16-100-50	M16	100	50	41	1578	4200	✓	B 19,36 €
D-ZY16-100-55	M16	100	55	41	860	4200	-	B 20,34 €

*Depending on availability - Dimensions in mm

Our other products



PRF4590_E
Bracket for aluminium profile, PRF4590



BPHFclip
Clip for ball transfer unit, Insert clip - Installing from above



BOXdh
Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



HBM
Adjustment bushing for half-rail guide, Adjustment bushing



T5P_T10P
Connecting plate for T type timing belts, T5



GAL22
Conveyor wheel, Zinc plated steel



NDS20
Double cross clamp, Crossed



PO
Pull handle - Multi-sector, Tapped recessed insert




M2
Worm and wheel set, Unhardened steel



AZY_SS
Stainless steel cylindrical elastomount, Stainless steel



ACLLPP
Latch for aluminium profile, Spring operated latch

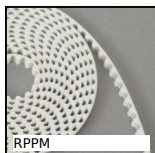

RPPM
RPP type belt per metre, RPP14 Steel cored polyurethane

Complementary products



DZYSS
Stainless steel cylindrical stop, stainless steel



EZY
Cylindrical stop, Steel



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA
Adjustable shock-absorber, Adjustable