



- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Progressive absorption of energy
- Materials
  - core: Steel plates
  - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

### Uses

- Shock-absorbing stop

### Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

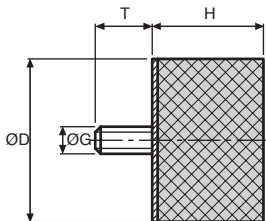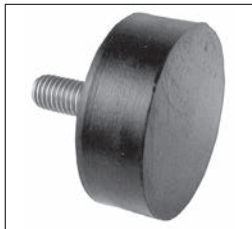

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)		
D-ZY4-10-10	M4	10	10	10	38	43	✓	A 1,16 €
D-ZY4-15-8	M4	15	8	10	122	95	✓	A 1,25 €
D-ZY4-15-10	M4	15	10	10	106	95	✓	A 1,42 €
D-ZY4-15-15	M4	15	15	10	74	95	✓	A 1,58 €
D-ZY6-20-15	M6	20	15	18	138	170	✓	A 1,77 €
D-ZY6-20-20	M6	20	20	18	-	-	✓	A 1,97 €
D-ZY6-20-25	M6	20	25	18	-	-	✓	A 1,97 €
D-ZY6-25-10	M6	25	10	18	-	-	✓	A 1,85 €
D-ZY6-25-15	M6	25	15	18	254	280	✓	A 2,04 €
D-ZY6-25-20	M6	25	20	18	128	280	✓	A 2,29 €
D-ZY6-25-25	M6	25	25	18	-	-	✓	A 2,47 €
D-ZY6-25-30	M6	25	30	18	80	280	✓	A 2,75 €
D-ZY8-30-20	M8	30	20	20	200	400	✓	A 3,07 €
D-ZY8-30-25	M8	30	25	20	-	-	✓	A 3,42 €
D-ZY8-30-30	M8	30	30	20	120	400	✓	A 3,87 €
D-ZY8-30-40	M8	30	40	20	-	-	✓	A 4,48 €
D-ZY8-40-20	M8	40	20	23	-	-	✓	A 4,21 €
D-ZY8-40-30	M8	40	30	23	23	234	✓	A 4,76 €
D-ZY8-40-40	M8	40	40	23	-	-	✓	A 5,00 €
D-ZY10-40-30	M10	40	30	28	-	-	✓	A 4,76 €
D-ZY10-50-20	M10	50	20	28	680	1000	✓	A 6,39 €
D-ZY10-50-30	M10	50	30	28	425	1000	✓	A 6,58 €
D-ZY10-50-40	M10	50	40	28	-	-	✓	A 7,22 €
D-ZY10-50-45	M10	50	45	28	-	-	-	A 7,63 €
D-ZY10-50-50	M10	50	50	28	-	-	✓	A 8,53 €
D-ZY10-60-40	M10	60	40	28	-	-	✓	A 12,58 €
D-ZY10-70-45	M10	70	45	28	-	-	-	A 16,27 €
D-ZY12-60-40	M12	60	40	33	-	-	✓	B 7,35 €
D-ZY12-75-25	M12	75	25	37	2000	2300	✓	B 6,98 €
D-ZY12-75-40	M12	75	40	37	810	2300	✓	B 10,53 €
D-ZY12-75-50	M12	75	50	37	-	-	-	B 10,97 €
D-ZY12-75-55	M12	75	55	37	-	-	✓	B 11,59 €
D-ZY16-100-50	M16	100	50	41	1578	4200	✓	B 19,36 €
D-ZY16-100-55	M16	100	55	41	860	4200	-	B 20,34 €

\*Depending on availability - Dimensions in mm

## Our other products



PAMF120  
Articulated fixable  
foot, pressed bolt-  
down base Ø 120, Ø  
120



BSM\_LOK  
Long-Lok spring  
plunger with internal  
hexagonal socket,  
LONG-LOK - s...



PM3  
Worm and wheel set,  
Non hardened steel



NPCR  
Adjustable cell  
support, Adjustable




PTMC  
Telescopic furniture  
foot, square plate



LWL  
Linear ball slide -  
Stainless steel balls,  
Chariot - from 514 N  
to 1...



ZBconique  
Machined plastic  
bevel gear, 1:1

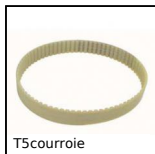

T5courroie  
T type timing belt, T5  
Steel cored  
polyurethane



VCMB  
Dual-thread screw  
wood/metal, Steel



HLUMss  
Revolving handle for  
handwheel, Stainless



LVT  
Miniature motorised  
actuator 2A, 2 amperes



NPR  
Reflector support,

## Complementary products



DZYSS  
Stainless steel  
cylindrical stop,  
stainless steel



EZY  
Cylindrical stop, Steel



MC  
Self-compensating  
shock-absorber, Self-  
compensating -  
without adjust...



RMSA  
Adjustable shock-  
absorber, Adjustable