



- Large degree of deformation accepted thus absorbing large amounts of energy
- Energy absorbed gradually
- Progressive absorption of energy
- Materials
 - core: Steel plates
 - cylinder: Rubber
- **Hardness: NK 55-60 shore A**
- Working temp: -40°C to +70°C

Uses

- Shock-absorbing stop

Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

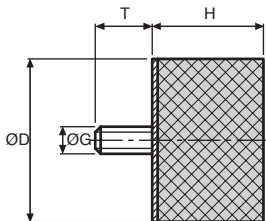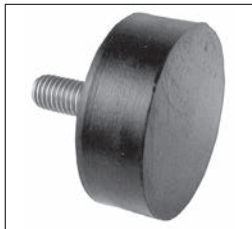

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)		
D-ZY4-10-10	M4	10	10	10	38	43	✓	A 1,16 €
D-ZY4-15-8	M4	15	8	10	122	95	✓	A 1,25 €
D-ZY4-15-10	M4	15	10	10	106	95	✓	A 1,42 €
D-ZY4-15-15	M4	15	15	10	74	95	✓	A 1,58 €
D-ZY6-20-15	M6	20	15	18	138	170	✓	A 1,77 €
D-ZY6-20-20	M6	20	20	18	-	-	✓	A 1,97 €
D-ZY6-20-25	M6	20	25	18	-	-	✓	A 1,97 €
D-ZY6-25-10	M6	25	10	18	-	-	✓	A 1,85 €
D-ZY6-25-15	M6	25	15	18	254	280	✓	A 2,04 €
D-ZY6-25-20	M6	25	20	18	128	280	✓	A 2,29 €
D-ZY6-25-25	M6	25	25	18	-	-	✓	A 2,47 €
D-ZY6-25-30	M6	25	30	18	80	280	✓	A 2,75 €
D-ZY8-30-20	M8	30	20	20	200	400	✓	A 3,07 €
D-ZY8-30-25	M8	30	25	20	-	-	✓	A 3,42 €
D-ZY8-30-30	M8	30	30	20	120	400	✓	A 3,87 €
D-ZY8-30-40	M8	30	40	20	-	-	✓	A 4,48 €
D-ZY8-40-20	M8	40	20	23	-	-	✓	A 4,21 €
D-ZY8-40-30	M8	40	30	23	23	234	✓	A 4,76 €
D-ZY8-40-40	M8	40	40	23	-	-	✓	A 5,00 €
D-ZY10-40-30	M10	40	30	28	-	-	✓	A 4,76 €
D-ZY10-50-20	M10	50	20	28	680	1000	✓	A 6,39 €
D-ZY10-50-30	M10	50	30	28	425	1000	✓	A 6,58 €
D-ZY10-50-40	M10	50	40	28	-	-	✓	A 7,22 €
D-ZY10-50-45	M10	50	45	28	-	-	-	A 7,63 €
D-ZY10-50-50	M10	50	50	28	-	-	✓	A 8,53 €
D-ZY10-60-40	M10	60	40	28	-	-	✓	A 12,58 €
D-ZY10-70-45	M10	70	45	28	-	-	-	A 16,27 €
D-ZY12-60-40	M12	60	40	33	-	-	✓	B 7,35 €
D-ZY12-75-25	M12	75	25	37	2000	2300	✓	B 6,98 €
D-ZY12-75-40	M12	75	40	37	810	2300	✓	B 10,53 €
D-ZY12-75-50	M12	75	50	37	-	-	-	B 10,97 €
D-ZY12-75-55	M12	75	55	37	-	-	✓	B 11,59 €
D-ZY16-100-50	M16	100	50	41	1578	4200	✓	B 19,36 €
D-ZY16-100-55	M16	100	55	41	860	4200	-	B 20,34 €

*Depending on availability - Dimensions in mm

 
Our other products



BPPss
Pressed stainless steel pillow block, Stainless steel



METEB
Self-lubricating blanks, Ferrous alloy (FP20)



BPF
Sheet steel flanged bearing for light loads, Sheet steel



LQT
Mechanical catch, Quick closing catch



DPAK_DKON
Progressive stop, Steel



PFC
Fixed rubber levelling foot, Levelling support for small parts



CHAL3
Piano hinge, Aluminium



MEB
Moulded plastic bevel gear (nylon), 1:1



 
PFC
Fixed rubber levelling foot, Levelling support



MCLred
Reducing sleeve female/female,



SLB
Indexing plunger, steel class 5.8



PF45
Worm and wheel gear reducer, up to 40 Nm

Complementary products



DZYSS
Stainless steel cylindrical stop, stainless steel



EZY
Cylindrical stop, Steel



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



RMSA
Adjustable shock-absorber, Adjustable