

- Compact cap nut



- Material:

Stainless steel 1.4404 (316L)

Polished finish

Advantages

- The surface of the cap nut is polished and is specially shaped for use in hygienic environments
- The head of the nut is hemispherical and the collar has a conical top face
- The overall height has been kept deliberately low to reduce any inconvenient edges to a minimum.

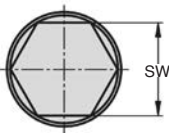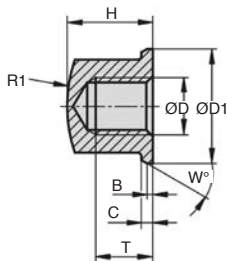

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	B	C	H	R1	SW	T	W	Price each
										1 to 4
EBC-3/HDSS	M3	6,8	0,25	0,5	4,95	8,8	5,5	3	20	3,40 €
EBC-4/HDSS	M4	9	0,30	0,8	6,5	10	7	4	30	3,43 €
EBC-5/HDSS	M5	10	0,50	1,0	7	16	8	4	30	3,61 €
EBC-6/HDSS	M6	12	0,80	1,0	9	16	10	6	30	4,41 €
EBC-8/HDSS	M8	16	0,80	1,6	12	20	13	8	30	4,56 €
EBC-10/HDSS	M10	20	1,00	2,0	14	32	16	10	30	5,48 €
EBC-12/HDSS	M12	24	1,00	2,5	16	35	19	11	30	10,63 €

All dimensions in mm

0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



TBEBASE10

Economic mini-table with trapezoidal leadscrew, 1kg



AT5P_AT10P

Connecting plate for AT type timing belts, AT5



NKIB

Combined bearing with inner ring, Axial load in both directions



TB8

Cylindrical roller thrust bearing, Steel



DB

Steel bevel gear, 2:1



BFD

Locking pin for bush, +180°C



BIMSS

Indexing plunger mini, miniature - Stainless steel



RHTtcss

High Temperature Castor, up to 200kg



YG2

HEAVY DUTY spur gear, Steel 35NCD6



AC144

Strike for toggle latch, 22mm



M2

Worm and wheel set, Unhardened steel



SHW

Plain washer, A2 Stainless steel

Complementary products



DEP

Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...