

- Compact cap nut



- Material:

Stainless steel 1.4404 (316L)

Polished finish

Advantages

- The surface of the cap nut is polished and is specially shaped for use in hygienic environments
- The head of the nut is hemispherical and the collar has a conical top face
- The overall height has been kept deliberately low to reduce any inconvenient edges to a minimum.

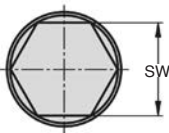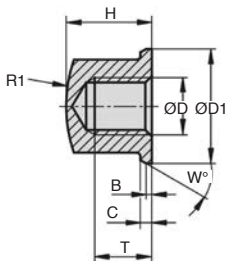

DISCOUNTS


Qty	1+	5+	10+	25+	50+
Disc	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	B	C	H	R1	SW	T	W	Price each
										1 to 4
EBC-3/HDSS	M3	6,8	0,25	0,5	4,95	8,8	5,5	3	20	3,40 €
EBC-4/HDSS	M4	9	0,30	0,8	6,5	10	7	4	30	3,43 €
EBC-5/HDSS	M5	10	0,50	1,0	7	16	8	4	30	3,61 €
EBC-6/HDSS	M6	12	0,80	1,0	9	16	10	6	30	4,41 €
EBC-8/HDSS	M8	16	0,80	1,6	12	20	13	8	30	4,56 €
EBC-10/HDSS	M10	20	1,00	2,0	14	32	16	10	30	5,48 €
EBC-12/HDSS	M12	24	1,00	2,5	16	35	19	11	30	10,63 €

All dimensions in mm

0 825 88 6000
 Service 0,15 € / min
 + prix appel

 Our other products



PF30NM
Worm and wheel gear reducer, up to 8.8 Nm



PSPD40
Flexible tube handle, Black PVC



VTHA
Magnetic screw with hexagonal head, Steel



CAP815
Slim slat top chain stainless steel, Narrow range 815



GTCCS
Belt tensioner, For use in hostile environments



ZG4
Plastic spur gear, Machined plastic (delrin)



 
G4
Steel spur gear, Steel 20NCD2



RHTplss
High Temperature Castor, up to 200kg



RBNtc
Swivel castor with central hole, Steel -



RPP8
RPP heavy duty timing belt, RPP8



VELM4
Screw-on base for hook-and-loop strip,



WJUM10
Drylin® W bearing block, Slide

Complementary products



DEP
Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...