

- Compact cap nut



- Material:

Stainless steel 1.4404 (316L)

Polished finish

Advantages

- The surface of the cap nut is polished and is specially shaped for use in hygienic environments
- The head of the nut is hemispherical and the collar has a conical top face
- The overall height has been kept deliberately low to reduce any inconvenient edges to a minimum.

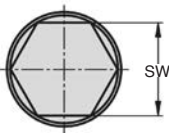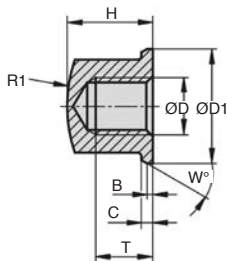

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc	Net	-5%	-10%	-15%	On request

Part N°	ØD	ØD1	B	C	H	R1	SW	T	W	Price each
										1 to 4
EBC-3/HDSS	M3	6,8	0,25	0,5	4,95	8,8	5,5	3	20	3,40 €
EBC-4/HDSS	M4	9	0,30	0,8	6,5	10	7	4	30	3,43 €
EBC-5/HDSS	M5	10	0,50	1,0	7	16	8	4	30	3,61 €
EBC-6/HDSS	M6	12	0,80	1,0	9	16	10	6	30	4,41 €
EBC-8/HDSS	M8	16	0,80	1,6	12	20	13	8	30	4,56 €
EBC-10/HDSS	M10	20	1,00	2,0	14	32	16	10	30	5,48 €
EBC-12/HDSS	M12	24	1,00	2,5	16	35	19	11	30	10,63 €

All dimensions in mm

0 825 88 6000
 Service 0,15 € / min
 + prix appel

Our other products



CABma

Swaging sleeve for fitting cable, To crimp a wire rope



F7-1

Multifunction display, With internal sensor



B3PAN

Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



UGH20

H Type Guide units, For Ø20 actuators



SSDB

Stainless steel bevel gear, 2:1




PSG08

Spur gear - precision range, Case hardened steel 20NCD2



FF15

 Offset spur gear reducer, from 2.20 to 10 Nm



PF30

Worm and wheel gear reducer, up to 8.80 Nm



ZG0

Plastic spur gear, Machined plastic (delrin)



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with



H0

Crossed helical gear crossed axis at 90°, Steel 20NCD2



E30

Right angle helical reducers, from 1.50 to 9 Nm

Complementary products



DEP

Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...