


- Drawn steel wire, tolerance h9, overall tolerance 10
- 2 hexagonal nuts
- Material:
Zinc plated (8µm) steel A37 with corrosion protection.
- Not sold individually, please contact us for details

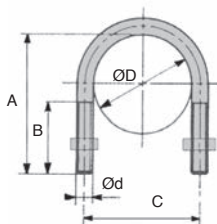

DISCOUNTS

Qty	1+	101+	201+	301+	401+	501+
Disc. Prix	-5%	-10%	-15%	-20%	On request	

Part number	For tube ØExternal ØD	Ø internal d	Keylines Ød	A (mm)	B (mm)	C (mm)	Stock*	Price each 1 to 100
EBM013	13	1/4	M6	28	18	19	✓	0,25 €
EBM017	17	3/8	M6	39	22	23	✓	0,27 €
EBM021	21	1/2	M6	41	24	27	✓	0,30 €
EBM027	27	3/4	M8	50	30	35	✓	0,42 €
EBM034	34	1	M8	55	32	42	✓	0,47 €
EBM042	42	1 ^{1/4}	M8	68	35	50	✓	0,47 €
EBM049	49	1 ^{1/2}	M8	70	36	57	✓	0,49 €
EBM060	60	2	M8	80	36	68	✓	0,56 €
EBM070	70	2 ^{1/4}	M8	100	40	78	✓	0,88 €
EBM076	76	2 ^{1/2}	M8	110	40	84	✓	0,88 €
EBM089	89	3	M10	116	40	99	✓	1,26 €
EBM102	102	3 ^{1/4}	M10	130	40	112	-	1,44 €
EBM108	108	3 ^{1/2}	M10	135	40	118	-	1,98 €
EBM114	114	4	M10	156	40	124	-	2,11 €
EBM133	133	4 ^{1/4}	M10	175	40	143	-	2,59 €
EBM139	139	5	M10	195	55	149	-	3,40 €
EBM159	159	5 ^{1/2}	M12	195	50	171	-	3,96 €
EBM168	168	6	M12	200	55	180	-	4,01 €
EBM219	219	8	M14	270	50	233	-	7,21 €

*Depending on availability - Dimensions in mm

Our other products



CHAEss

Decorative hinge,
Stainless steel



BSM_LOK

Long-Lok spring
plunger with internal
hexagonal socket,
LONG-LOK - s...



CHAE4080PA

Symmetrical decorative
screwed hinge,
Polyamide



DOMI30

Connecting kits, XY
linking kit



 
ACLCHAR

Hinge for aluminium
profile, With
elongated holes



PLA

Flat magnet, Flat
magnet with threaded
hole



QNJ

Single row cylindrical
roller bearing, Single
flange on inner ring



MRASeco

Low cost stainless
steel quick link,
Stainless steel



CHAC4040SS

Square hinge with
riveted pin, drilled,
Square with riveted



GMK17_BROSSE

Brush strip, Cone-
shaped - brush



LACT_SS

Adjustable Stainless
steel cam lever, Male



VELprf

Clip-on base for hook-
and-loop strip,
Polyamide

Complementary products



EIM

Stainless steel U bolt,
Stainless steel