


- Drawn steel wire, tolerance h9, overall tolerance 10
- 2 hexagonal nuts
- Material:
Zinc plated (8µm) steel A37 with corrosion protection.
- Not sold individually, please contact us for details

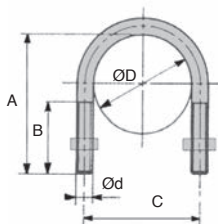

DISCOUNTS

Qty	1+	101+	201+	301+	401+	501+
Disc. Prix	-5%	-10%	-15%	-20%	On request	

Part number	For tube ØExternal ØD	Ø internal d	Keylines Ød	A (mm)	B (mm)	C (mm)	Stock*	Price each 1 to 100
EBM013	13	1/4	M6	28	18	19	✓	0,25 €
EBM017	17	3/8	M6	39	22	23	✓	0,27 €
EBM021	21	1/2	M6	41	24	27	✓	0,30 €
EBM027	27	3/4	M8	50	30	35	✓	0,42 €
EBM034	34	1	M8	55	32	42	✓	0,47 €
EBM042	42	1 ^{1/4}	M8	68	35	50	✓	0,47 €
EBM049	49	1 ^{1/2}	M8	70	36	57	✓	0,49 €
EBM060	60	2	M8	80	36	68	✓	0,56 €
EBM070	70	2 ^{1/4}	M8	100	40	78	✓	0,88 €
EBM076	76	2 ^{1/2}	M8	110	40	84	✓	0,88 €
EBM089	89	3	M10	116	40	99	✓	1,26 €
EBM102	102	3 ^{1/4}	M10	130	40	112	-	1,44 €
EBM108	108	3 ^{1/2}	M10	135	40	118	-	1,98 €
EBM114	114	4	M10	156	40	124	-	2,11 €
EBM133	133	4 ^{1/4}	M10	175	40	143	-	2,59 €
EBM139	139	5	M10	195	55	149	-	3,40 €
EBM159	159	5 ^{1/2}	M12	195	50	171	-	3,96 €
EBM168	168	6	M12	200	55	180	-	4,01 €
EBM219	219	8	M14	270	50	233	-	7,21 €

*Depending on availability - Dimensions in mm

Our other products



WINGbr

Wing screw, hand tightened DIN316, Brass DIN 316



CLB_M

Die cast zinc clamping lever - female, Zamak



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm



MHPGR

Arm with folding rotating handle,



VTLF

3 lobed handle, Polyamide - Brass



RTT

Locking Assembly, Medium/high torque



SVR15

Screwjack with travelling nut, with moving nut



PRF-SMA

Closing system for aluminium profile, Easily adjustable lock



RT61

Self-centering locking Assembly,



CHTRB

Single and dual output gearboxes, Up



AT5M AT10M

AT type timing belt per metre, AT5 Steel



PSPD40

Flexible tube handle, Black PVC

Complementary products



EIM

Stainless steel U bolt, Stainless steel