

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

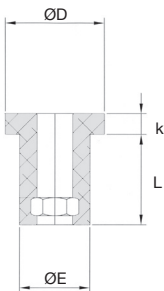

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products



CHM110
Worm and wheel gear reducer, up to 980 Nm



PCLA_M
Technopolymer clamping lever - female, Plastic



LVT
Miniature motorised actuator 2A, 2 amperes



SSDB
Stainless steel bevel gear, 2:1



PT820
Drive sprocket for slat top chain, Ranges 820 and 815



AKN
Bellows coupling Gerwah®, from 22 to 180Nm



CAP882
Flexible slat top chain acetal, Large range 882



T39_T49
Extension spring in metre length steel, by the metre



RURp
Wheel pivoting with plate, Polyurethane -



RFV63
Stainless steel worm and wheel gearbox,



EKONSL
Silicone conical elasto buffer, Female



PT882
Drive sprocket for slat top chain, Range 882

Complementary products