

- Flanged chloroprene elastomer moulded into a nut



### Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
  - Compression - shearing
  - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



### Info.

- Not sold individually, please contact us for details

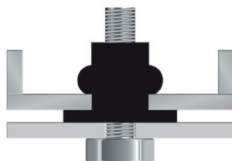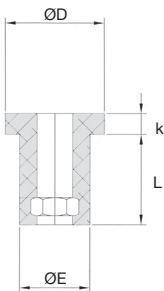

Mounting type 1



Mounting type 2

### DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

\*Depending on availability - Dimensions in mm

## Our other products



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



RGS

Rotex® GS backlash free jaw coupling, from 0.5 to 190Nm



TSRTC

Stem support for caster, For swivel caster with central hole



KB\_OP

Open precision linear bearing, Precision - steel



NT61

Spur gear coaxial gearbox, from 5 to 14 Nm - Inline




PRF\_ART

Articulated bracket for use with aluminium profile, With clamping ha...




PRF\_BM

Base support plate for aluminium profile, Central base fixation

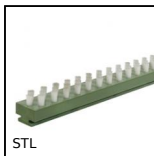

STL

 Guidance brush - Brush, Brush



GPLac

Brush, steel



LSM

Stainless steel 316L lead screw, Stainless



F7-SF-SM

Multifunction display, Mounting bracket for



GMC\_GMK\_BR

Guiding profile clamp, Flat or rounded

Complementary products